



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
Base: shiny 304 stainless steel sheet
Thread: 304 stainless steel, supplied without nut
Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

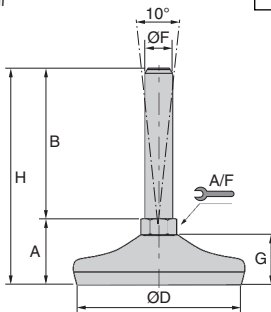

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	29,62€
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	31,76€
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	31,76€
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	33,84€
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	35,47€
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	38,07€
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	42,04€

* Depending on availability - Dimensions in mm

Our other products




BLH20

Right angled gearbox, from 0.53 to 1.77



RCC_RCX

Spherical tilt washer - DIN 6319, concave

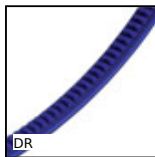

DR

Plastic flexible rack, Rack



DOG319

DC Motor and gearbox combination, from 4 to 9 Nm



E50

Angle transmission gearbox, from 3 to 41 Nm



MEB

Moulded plastic bevel gear (nylon), 1:1



GE1006

Flexible toggle latch, Hooks into a slot



PAMF80EB

Articulated foot with sheet metal base, Articulated foot



INS_SS

Self tapping insert, Stainless steel



V3RA_PTR

Hand wheel, Polyamide



SFE

Rod end, Stainless steel / PTFE



RT70

Locking Assembly, Medium/high torque

Complementary products



PTA50ssEB

Articulated foot with sheet metal base, Articulated foot



PTA100ssEB

Articulated foot with sheet metal base, Articulated foot



PAMF80EB

Articulated foot with sheet metal base, Articulated foot



PAMF100EB

Articulated foot with sheet metal base, Articulated foot

Altri prodotti...



PML

Piede massiccio per carichi pesanti, Ø 100, 120 o 150



RHTtcss

Ruota alte temperature con foro centrale, fino a 200kg



G-ECO

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



ZB

Albero per guida lineare, Inox temprato



DILC

Indexing plunger with cam, with cam



BFDdII

Boccola di fermo per perno ad innesto, Acciaio nichelato



CHN CHNSS

Catena dritta a maglie lunghe, Inox



BLHB40

Rinvio angolare ad albero cavo, fino a 10.3 Nm



PR880

Ruota di rinvio, Serie 880



CAP820

Catena a tapparella dritta, Stretta serie 820



HFL

Ruota libera, Combinata ad aghi



VAP

Magnete con foro centrale, Con foro centrale

Prodotti correlati



PTA50ssEB

Piede snodato con base stampata Ø50, Piede snodato



PTA100ssEB

Piede snodato con base stampata Ø100, Piede snodato



PAMF80EB

Piede snodato con base stampata fissabile Ø80, Piede snodato



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato