



# Stainless steel swivelling foot, bolt-down

## PTKFSS

### Max load 25,000N

#### - "Teknohygienic" swivelling foot

#### - Materials:

Base: stainless steel 304

Stem: stainless steel 304

Blind nut: stainless steel 304

#### - Sole: NBR rubber Shore hardness 90°

**For the food industry**

*Avoids water retention*

**stainless steel**

### Advantages

- The 3-A standard designates products that are designed for the dairy, food and pharmaceutical industries where strict hygiene rules apply.


- Smooth finished foot with a wiper seal between the stem and the nut and around the swivel to prevent accumulation of dirt or retention of water

- Suitable for cleaning with water or chemicals

- USDA approved

### Info.

- Do not forget to order the PTKF-M12/SS 3-A approved blind nut

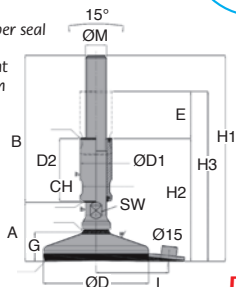

Blind M12 nut

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Adjustable range	ØM	E	A	B	ØD	SW	ØD1	D2	CH	H2	H3	H1	I	Static load (N)	Price each 1 to 5
PTKF80-16-140/SS	M16	45	53	140	80	13	24	60	20	114	159	193	54	20000	100,12 €	
PTKF80-16-190/SS	M16	70	53	190	80	13	24	85	20	139	209	243	54	20000	102,96 €	
PTKF80-20-140/SS	M20	45	53	140	80	17	30	60	26	114	159	193	54	20000	90,56 €	
PTKF80-20-142/SS	M20	55	53	142	80	17	30	70	26	123	178	195	54	20000	93,44 €	
PTKF80-20-190/SS	M20	70	53	190	80	17	30	85	26	139	209	243	54	20000	103,84 €	
PTKF80-24-140/SS	M24	45	53	140	80	20	35	60	30	114	159	193	54	20000	94,04 €	
PTKF80-24-190/SS	M24	70	53	190	80	20	35	85	30	139	209	243	54	20000	110,69 €	
PTKF100-16-140/SS	M16	45	56	140	100	13	24	60	20	117	162	196	69	25000	91,44 €	
PTKF100-16-190/SS	M16	70	56	190	100	13	24	85	20	142	212	246	69	25000	107,99 €	
PTKF100-20-140/SS	M20	45	56	140	100	17	30	60	26	117	162	196	69	25000	95,58 €	
PTKF100-20-190/SS	M20	70	56	190	100	17	30	85	26	142	212	246	69	25000	108,88 €	
PTKF100-24-140/SS	M24	45	56	140	100	20	35	60	30	117	162	196	69	25000	103,14 €	
PTKF100-24-190/SS	M24	70	56	190	100	20	35	85	30	142	212	246	69	25000	115,71 €	
PTKF100-30-135/SS	M30	40	56	135	100	26	42	60	36	117	157	191	69	25000	112,83 €	
PTKF100-30-185/SS	M30	65	56	185	100	26	42	85	36	142	207	241	69	25000	122,89 €	

#### Blind M12 nut

PTKF-M12/SS	M12															13,55 €
-------------	-----	--	--	--	--	--	--	--	--	--	--	--	--	--	--	---------

Dimensions in mm

## Altri prodotti...



Gal-cardan

Giunto cardanico  
semplice serie eco,  
Sollecitazioni leggere



ZBconique

Ingranaggio conico in  
plastica, 1:1




RBGpl

Ruota fissa con  
piastra, Acciaio -  
gomma grigia



PSG08HC

Ingran. dritto di  
precisione trattato  
skiving, Acciaio  
20NCD2 cement...

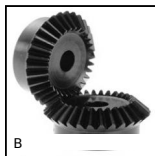

B

Ingranaggio conico -  
Acciaio 60C40, 1:1



PRF\_ROUL\_F

Ruota per profili  
alluminio, Con freno



GMK17\_R

Guida prodotto  
laterale tonda, Per  
imbottigliamento e  
imballaggio



G2

Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



TAC\_SS

Tenditore, Inox



CHML40

Riduttore a ruota e  
vite senza fine, fino a  
57 Nm - Con



TFR

Tenditore rigido, Fisso



RTTss

Calettatore di  
bloccaggio, Coppia  
media/elevata

## Prodotti correlati



PTKFss

Piede fissabile  
speciale  
agroalimentare,  
Stainless steel - 3-A

stand...