



Stainless steel swivelling foot, bolt-down

PTKFSS

Max load 25,000N

- "Teknohygienic" swivelling foot

- Materials:

Base: stainless steel 304

Stem: stainless steel 304

Blind nut: stainless steel 304

- Sole: NBR rubber Shore hardness 90°

For the food industry

Avoids water retention

stainless steel

Advantages

- The 3-A standard designates products that are designed for the dairy, food and pharmaceutical industries where strict hygiene rules apply.


- Smooth finished foot with a wiper seal between the stem and the nut and around the swivel to prevent accumulation of dirt or retention of water

- Suitable for cleaning with water or chemicals

- USDA approved

Info.

- Do not forget to order the PTKF-M12/SS 3-A approved blind nut

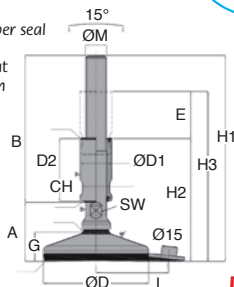

Blind M12 nut

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Adjustable range	ØM	E	A	B	ØD	SW	ØD1	D2	CH	H2	H3	H1	I	Static load (N)	Price each 1 to 5
PTKF80-16-140/SS	M16	45	53	140	80	13	24	60	20	114	159	193	54	20000	100,12 €	
PTKF80-16-190/SS	M16	70	53	190	80	13	24	85	20	139	209	243	54	20000	102,96 €	
PTKF80-20-140/SS	M20	45	53	140	80	17	30	60	26	114	159	193	54	20000	90,56 €	
PTKF80-20-142/SS	M20	55	53	142	80	17	30	70	26	123	178	195	54	20000	93,44 €	
PTKF80-20-190/SS	M20	70	53	190	80	17	30	85	26	139	209	243	54	20000	103,84 €	
PTKF80-24-140/SS	M24	45	53	140	80	20	35	60	30	114	159	193	54	20000	94,04 €	
PTKF80-24-190/SS	M24	70	53	190	80	20	35	85	30	139	209	243	54	20000	110,69 €	
PTKF100-16-140/SS	M16	45	56	140	100	13	24	60	20	117	162	196	69	25000	91,44 €	
PTKF100-16-190/SS	M16	70	56	190	100	13	24	85	20	142	212	246	69	25000	107,99 €	
PTKF100-20-140/SS	M20	45	56	140	100	17	30	60	26	117	162	196	69	25000	95,58 €	
PTKF100-20-190/SS	M20	70	56	190	100	17	30	85	26	142	212	246	69	25000	108,88 €	
PTKF100-24-140/SS	M24	45	56	140	100	20	35	60	30	117	162	196	69	25000	103,14 €	
PTKF100-24-190/SS	M24	70	56	190	100	20	35	85	30	142	212	246	69	25000	115,71 €	
PTKF100-30-135/SS	M30	40	56	135	100	26	42	60	36	117	157	191	69	25000	112,83 €	
PTKF100-30-185/SS	M30	65	56	185	100	26	42	85	36	142	207	241	69	25000	122,89 €	

Blind M12 nut

PTKF-M12/SS	M12															13,55 €
-------------	-----	--	--	--	--	--	--	--	--	--	--	--	--	--	--	---------

Dimensions in mm

Altri prodotti...



PP60

Riduttore a ruota e vite senza fine, da 17.80 a 34 Nm



CHTRB

Riduttore a rinvio angolare a L o a T, fino a 4,7 Nm



SVR30

Martinetto a vite - Vite rotante, Con madrevite esterna



LM

Attacco per forcella, Corta acciaio




GSI

Molla a gas inox, Inox



ACL-PLAngle

Elementi di giunzione, Collegamento angolare

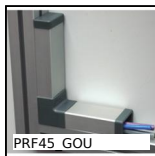

PRF45 GOU

Canalina, Accessori



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2




CHMBR

Braccio di reazione, Braccio di reazione per riduttori CHM e



DOG111

Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm

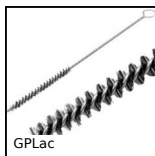

GPLac

Scovolo, acciaio



PM4

Coppia ruota e vite senza fine, Plastica lavorata (delrin)

Prodotti correlati



PTKFss

Piede fissabile speciale agroalimentare, Stainless steel - 3-A

stand...