

- Allows vacuum suction cups to be integrated into a handling system

- Materials :

Aluminium



Screws : steel

### Advantages

- Infinitely variable angle of adjustment

- Easy, flexible mounting

**NEW!**

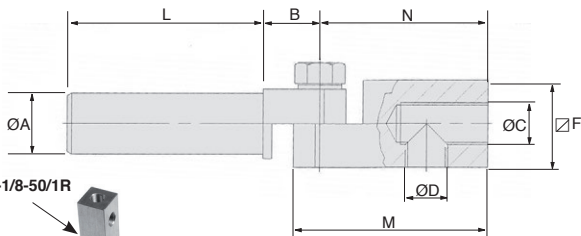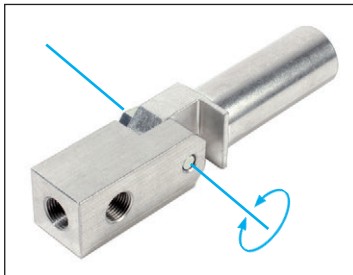

PV20-1/8-50/1R

BAN20/U

Typical application

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	ØC	ØD	L	M	∇F	N	Weight (g)	Price each 1 to 9
PV20-1/8-50/1R	20	15	G1/8"	G1/8"	50	47	20	41	72	47,53 €
PV20-1/8-100/1R	20	15	G1/8"	G1/8"	100	47	20	41	87	49,57 €
PV20-1/8-150/1R	20	15	G1/8"	G1/8"	150	47	20	41	103	51,60 €
PV20-1/4-50/1R	20	15	G1/4"	G1/4"	50	49	25	43	93	48,55 €
PV20-1/4-100/1R	20	15	G1/4"	G1/4"	100	49	25	43	106	50,59 €
PV20-1/4-150/1R	20	15	G1/4"	G1/4"	150	49	25	43	123	52,62 €

Dimensions in mm

## Altri prodotti...



AT10courroie

Cinghia di  
posizionamento AT,  
AT10 Poliuretano  
armatura in acciaio



CHB

Braccio di reazione,  
Braccio di reazione  
per riduttori CHB



RBNpl

Ruota girevole a  
doppio bloccaggio,  
Acciaio - caucciù



CHAR5050\_Z

Cerniera a molla,  
avvitabile



SBRtool

Chain tool, Drive  
chain maintenance  
tools



RAM30

Riduttore manuale,  
Rinvio angolare



PRF\_GAL

Rotella per profilo  
alluminio, Rotella  
cava  $\varnothing 12$



CLASS

Maniglia a ripresa -  
maschio, Inox



G0

Ingranaggio dritto  
acciaio, Acciaio




VTA

Limitatore di coppia  
ad attrito Vari-Tork®,



TIFss

Tirante tutto filetto -  
DIN976A, Inox

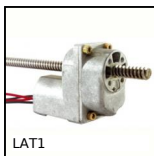

LAT1

Attuatore lineare a  
motore 1A, 1 ampere

## Prodotti correlati



PV2R

Braccio portaventosa  
orientabile, Serraggio  
rinforzato