

- Allows vacuum suction cups to be integrated into a handling system

- Materials :

Aluminium



Screws : steel

Advantages


- Infinitely variable angle of adjustment

- Easy, flexible mounting

NEW!

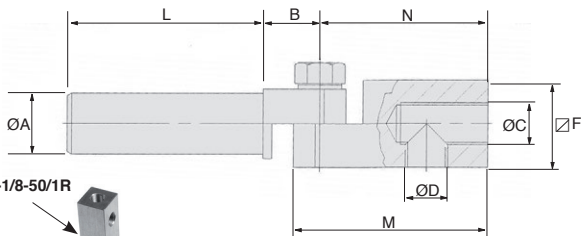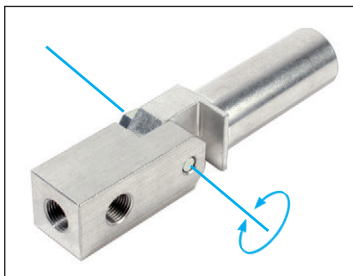

PV20-1/8-50/1R

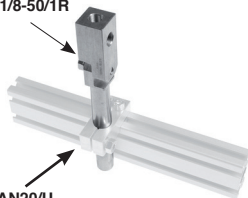

BAN20/U

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	ØC	ØD	L	M	∇F	N	Weight (g)	Price each 1 to 9
PV20-1/8-50/1R	20	15	G1/8"	G1/8"	50	47	20	41	72	47,53 €
PV20-1/8-100/1R	20	15	G1/8"	G1/8"	100	47	20	41	87	49,57 €
PV20-1/8-150/1R	20	15	G1/8"	G1/8"	150	47	20	41	103	51,60 €
PV20-1/4-50/1R	20	15	G1/4"	G1/4"	50	49	25	43	93	48,55 €
PV20-1/4-100/1R	20	15	G1/4"	G1/4"	100	49	25	43	106	50,59 €
PV20-1/4-150/1R	20	15	G1/4"	G1/4"	150	49	25	43	123	52,62 €

Dimensions in mm

Altri prodotti...



Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...



Manicotto a sfere Mini, Miniatura



Ingranaggio conico inox, 2:1



Antivibrante elastico cilindrico inox, Inox



Giunto a soffietto Gerwah®, da 22 a 600Nm



Boccola di fermo per perno ad innesto, Acciaio nichelato



Ruota fissa con piastra, Acciaio - caucciù



Cerniera a molla, avvitabile



Rondella sferica - DIN6319, convessa



Blocchetto di fissaggio, Aggiunta e fissaggio di pannelli



Contenitore a becco, 8mm



Supporto a flangia ovale con cuscinetto, Lamiera

Prodotti correlati



Braccio portaventosa orientabile, Serraggio rinforzato