
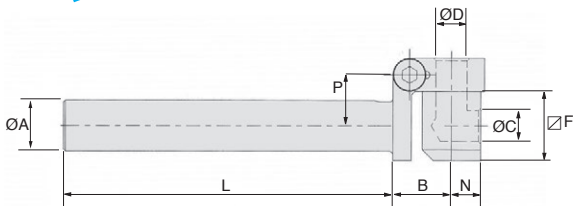


- Allows vacuum suction cups to be integrated into a handling system
- Materials :  
Aluminium  
Screws : steel

### Advantages

- Infinitely variable angle of adjustment
- No circlips required

**NEW!**

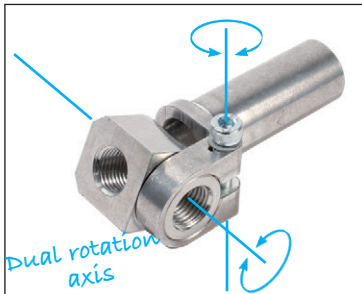

Exploded view



### DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	65,77 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	68,41 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	72,37 €

Dimensions in mm

## Altri prodotti...




PRF\_FIX\_UNI  
Fissaggio, universale



Q6  
Cuscinetto radiale a  
sfere, Acciaio



J51  
Riduttore coassiale a  
treni paralleli, da 0.13  
a 0.49 - a treni para...

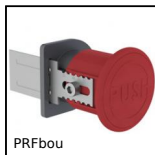


PRFbou  
Sistema di chiusura,  
Pulsante apriporta di  
emergenza



RPCtss  
Ruota girevole a foro  
centrale, Inox -  
Poliamide - a doppio  
bloccag...



PRF\_ROUL\_F  
Ruota per profili  
alluminio, Con freno

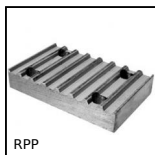

RPP  
Piastra di giunzione  
per cinghia RPP, RPP5




GMK17\_RG  
Morsetto di giunzione,  
Per guida prodotto  
laterale



QNJ  
Cuscinetto a singola  
corona di rulli  
cilindrici, Anello  
interno fiss...



AK  
Giunto a soffietto  
Gerwah®, da 36 a  
800Nm

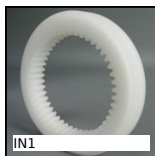

IN1  
Ingranaggio interno,  
Plastica lavorata  
(delrin)



BSM  
Pressore a molla con  
esagono incassato,  
corpo e spina in  
acciaio

Prodotti correlati