
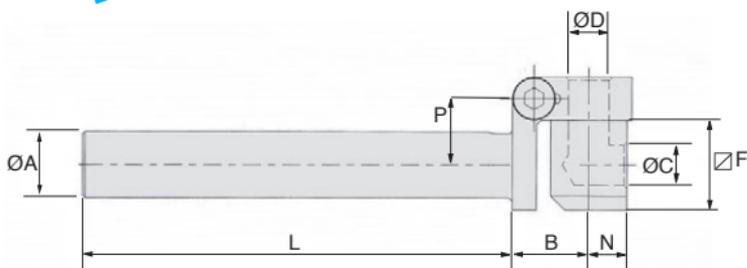


- Allows vacuum suction cups to be integrated into a handling system
- Materials :
Aluminium
Screws : steel

Advantages

- Infinitely variable angle of adjustment
- No circlips required

NEW!

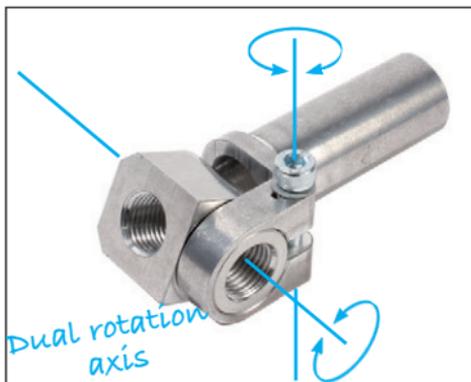

Exploded view



DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	65,77 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	68,41 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	72,37 €

Dimensions in mm

Altri prodotti...



GP75

Chiusura a leva molla a trazione compensata, Standard (GP75)



RMSA

Deceleratore, Regolabile



RJA10_03

Guarnizione in gomma, Da agganciare



SH1

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



PRES

Accessori per pressa PRES-3HR e PRES-4HR, Portapinzette



HW_HT

Guida su semi-binari, Binario



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2



TBEBASE

Base plate for economic mini-table, Allows X-Y cross tables



BAG-MI

Anello di serraggio con intaglio e



PRF_CLIP_22

Clip di fissaggio per cavi per profili



APBC

Supporto per sensore, Tubo di collegamento



T25-BAR

Barra dentata, T2.5

Prodotti correlati