
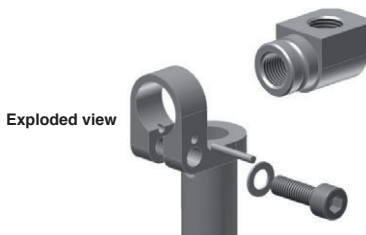
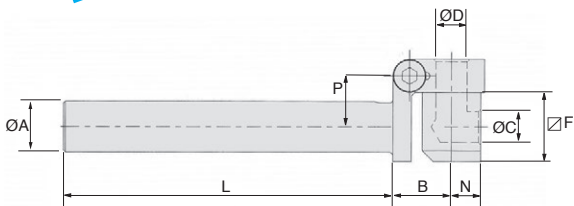


- Allows vacuum suction cups to be integrated into a handling system
- Materials :
Aluminium
Screws : steel

Advantages

- Infinitely variable angle of adjustment
- No circlips required

NEW!

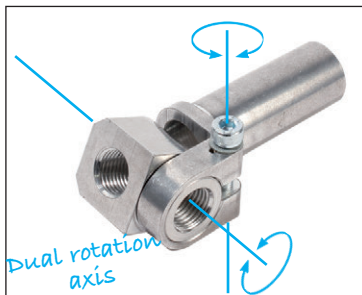

DISCOUNTS

Qty	1+	10+	30+
Disc.	List -5%	On request	

Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	65,77 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	68,41 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	72,37 €

Dimensions in mm

Altri prodotti...



PRES5HR
Pressa manuale da banco, Pressione fino a 500kg



PAT85
Piede snodato con base stampata Ø85, Ø 85



DOMI50
Kit di raccordo, Kit di raccordo XZ




PAP
Maniglia e battuta per porta, Maniglia ergonomica



PGNT
Impugnatura termoplastica a T, Con inserto maschiato



CFS
Perno folle mini, Miniatura

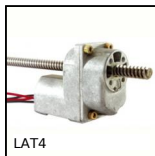

LAT4
Attuatore lineare a motore 4A, 4 ampere



CFF
Testa a snodo femmina DIN ISO12240-4, Acciaio / bronzo




BABpss
Perno autobloccante, Inox



ACLEPP
Angolare, 8 fori



M1
Coppia ruota e vite senza fine, Acciaio temprato

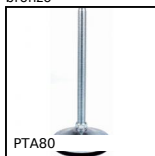

PTA80
Piede snodato con base stampata Ø80, Ø 80

Prodotti correlati