

# Carrying handle

PX  
PO


Steel

## Handle PX399-BR:

- The plate and ring of the handle are not attached
- Plate: 1mm thick formed steel
- Ring: formed wire Ø4.9mm

## Handle PO301-ZB:




- Reduced height saves space
- Ring is secured to plate
- Two part riveted plate, 1.5mm
- 5 fixing holes Ø5.5mm
- Ring: Formed steel wire 8mm
- Plate secured using 4 x light alloy rivets Ø3mm

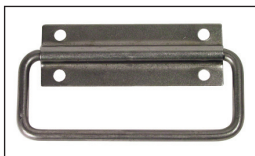

Handle PX399-BR



Handle PO301-ZB

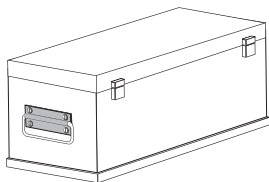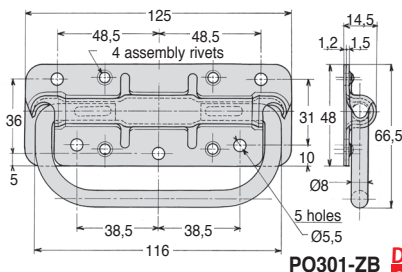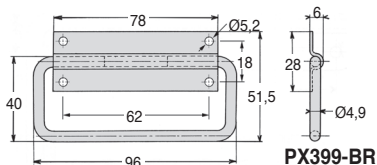

## DISCOUNTS

Qty.	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Finish	Fixing	Max. load per handle (kgf)	Weight (kg)	Stock	Price each 1 to 5
<b>Ordinary carry handle</b>						
PX399-BR	Unfinished	With hole	-	0,049	✓	1,25 €
<b>Riveted carrying handle</b>						
PO301-ZB	Zinc plated steel	With hole	60	0,023	✓	7,29 €

\*Depending on availability

## Altri prodotti...



DOG111

Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm



CF

Perno folle, Standard - acciaio



RPB

Vite a ricircolo di sfere, Supporto



S4

Pignone a catena - Inox, 4mm



PTKFss

Piede speciale agroalimentare, Dado cieco inox - norme 3A



ADL\_F

Anello di sollevamento, Inox



PML

Piede massiccio per carichi pesanti, Ø 100, 120 o 150



BC3

Panamech, Multi-Beam inox - con ganascia di serraggio



AC

Piastrina di riscontro, 12,13,18 e 20mm



PP35

Riduttore a ruota e vite senza fine, da 2.20 a 4.10 Nm



PTA80


Piede snodato con base stampata Ø80, Ø 80



BABFCFO

Perno autobloccante, Boccole di fissaggio con flangia cilindrica

## Prodotti correlati

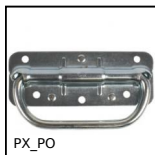

PX\_PO

Maniglia - movimentazione manuale, con piastra posteriore