

# Double row **angular** contact ball bearings **New**


## Q3

## Steel

- Double row angular contact bearings are capable of handling axial and radial loads
- Static and dynamic loads are radial loads
- Materials:
  - Steel rings and balls
  - Polyamide cage

### Advantage

- The special feature of this type of bearing is that gives the equivalent performance of two single row bearings but with a reduced axial dimension.

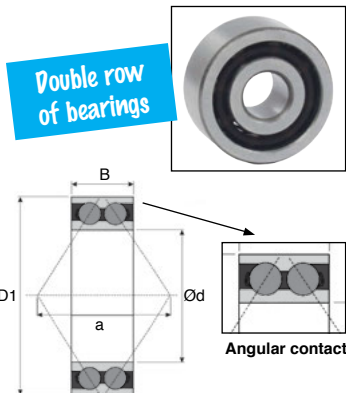

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List -10%	-15%	-20%	-30%	On request	

Part number	Ød	ØD1	B	a	Load (kN)		Speed (rpm)		Weight (kg)	Price each 1 to 5
					Dynamic (C)	Static (Co)	Grease	Oil		
Q3200-ATN9	10	30	14,0	16	7,50	4,21	18360	21600	0,051	5,89 €
Q3201-ATN9	12	32	15,9	19	9,90	5,49	16830	19800	0,0580	6,76 €
Q3202-ATN9	15	35	15,9	21	11,00	6,66	13770	16200	0,0660	7,41 €
Q3203-ATN9	17	40	17,5	23	14,00	8,62	12240	14400	0,0950	7,52 €
Q3204-ATN9	20	47	20,6	28	19,60	11,76	10710	12600	0,1600	8,43 €
Q3304-ATN9	20	52	22,2	30	23,10	14,31	9945	11700	0,2200	15,31 €
Q3205-ATN9	25	52	20,6	30	21,20	14,01	9180	10800	0,1900	9,67 €
Q3305-ATN9	25	62	25,4	36	31,40	19,99	8415	9900	0,3500	16,93 €
Q3206-ATN9	30	62	23,8	36	29,40	19,99	7650	9000	0,2900	12,84 €
Q3306-ATN9	30	72	30,2	42	40,70	26,95	6885	8100	0,5300	21,76 €
Q3207-ATN9	35	72	27,0	42	39,20	27,44	6885	8100	0,4400	14,43 €
Q3307-ATN9	35	80	34,9	47	51,00	34,79	6505	7650	0,7100	27,93 €
Q3208-ATN9	40	80	30,2	46	46,60	33,32	6120	7200	0,5800	22,10 €
Q3308-ATN9	40	90	36,5	53	62,70	43,12	5740	6750	1,0500	36,32 €
Q3209-ATN9	45	85	30,2	49	50,00	38,22	5740	6750	0,6400	24,68 €
Q3309-ATN9	45	100	39,7	58	73,50	51,94	5130	6030	1,4000	51,52 €
Q3210-ATN9	50	90	30,2	52	50,00	38,22	5355	6300	0,6600	27,37 €
Q3211-ATN9	55	100	33,3	57	58,80	46,55	4820	5670	1,0500	36,32 €
Q3311-ATN9	55	120	49,2	72	109,80	79,87	4055	4770	2,5500	93,10 €
Q3212-ATN9	60	110	36,5	63	72,00	57,33	4284	5040	1,4000	42,37 €

Dimensions in mm

## Altri prodotti...



DOMI30

Slitta di regolazione  
Domino 30, Slitta  
DOMILINE 30



MEB

Ingranaggio conico in  
plastica stampata, 1:1



PF55

Riduttore a ruota e  
vite senza fine, fino a  
57 Nm



RBGpl

Ruota girevole a  
doppio bloccaggio,  
Acciaio - gomma  
grigia



PGNT

Impugnatura  
termoplastica a T, Con  
perno filettato



WS16

Binario Drylin® W,  
Binario



BIMSS

Pistoncino a molla,  
Miniatura inox



LVT

Mini martinetto  
motorizzato 4A, 4  
ampere



ADL\_F

Anello di  
sollevamento, Inox



IN2

Ingranaggio interno,  
Acciaio 20NCd2



PRF\_ECL

Fissaggio, Dado  
quadrato con



PRF\_SDD\_1820

Supporto per sensore  
Ø18 e Ø20, ø18 e ø20

## Prodotti correlati




Q1

Cuscinetto orientabile  
a sfere, Acciaio



QTR

Cuscinetto a rulli  
conici, Acciaio

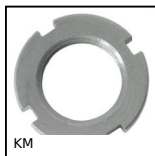

KM

Cuscinetto a sfere -  
Accessorio, Ghiera KM



EAR

Cuscinetto a sfere -  
Accessorio, Ghiera  
autobloccante - anello  
di fr...