

- Especially designed to handle combined axial and radial loads
- A demountable bearing, i.e. the inner ring and roller cage form a single element that can mounted separately from the external ring
- Static and dynamic loads are radial loads
- Materials:
 - Steel flanges and cylinders
 - Pressed steel cage




DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List -10%	-15%	-20%		On request

Part number	Ød	ØD1	T	B	A	Load (kN)		Load (rpm)		Weight (kg)	Price each 1 to 5
						Dynamic (C)	Static (Co)	lubricant Grease	Oil		
QTR30302	15	42	14,3	13	11	22	19	13770	16200	0,095	5,07 €
QTR30203	17	40	13,3	12	11	18	18	13770	16200	0,075	4,20 €
QTR30303	17	47	15,3	14	12	27	24	12240	14400	0,130	5,20 €
QTR32303	17	47	20,3	19	16	34	32	12240	14400	0,170	7,18 €
QTR32004	20	42	15,0	15	12	23	26	12240	14400	0,097	5,46 €
QTR30204	20	47	15,3	14	12	27	27	11475	13500	0,120	4,78 €
QTR30304	20	52	16,3	15	13	33	31	10710	12600	0,170	5,75 €
QTR32304	20	52	22,3	21	18	43	44	10710	12600	0,230	8,04 €
QTR32005	25	47	15,0	15	11,5	26	31	10710	12600	0,110	5,97 €
QTR30205	25	52	16,3	15	13	30	32	9945	11700	0,150	5,29 €
QTR32205	25	52	19,3	18	15	35	43	9945	11700	0,190	7,11 €
QTR33205	25	52	22,0	22	18	46	54	9945	11700	0,230	10,48 €
QTR30305	25	62	18,3	17	15	43	42	9180	10800	0,260	7,11 €
QTR32305	25	62	25,3	24	20	59	61	9180	10800	0,360	11,12 €
QTR32006	30	55	17,0	17	13	35	43	9180	10800	0,170	7,44 €
QTR30206	30	62	17,3	16	14	39	43	8415	9900	0,230	6,82 €
QTR32206	30	62	21,3	20	13	49	55	8415	9900	0,280	7,92 €
QTR33206	30	62	25,0	25	14	63	75	8415	9900	0,370	14,87 €
QTR31306	30	72	20,8	19	17	46	49	7268	8550	0,390	13,58 €
QTR32306	30	72	28,8	27	19,5	75	83	7650	9000	0,550	14,81 €
QTR32007	35	62	18,0	18	14	42	52	8415	9900	0,220	7,73 €
QTR30207	35	72	18,3	17	15	50	54	7268	8550	0,320	9,25 €
QTR32207	35	72	24,3	23	19	64	76	7268	8550	0,430	9,37 €
QTR33207	35	72	28,0	28	22	82	103	7268	8550	0,560	15,52 €
QTR30307	35	80	22,8	21	18	70	72	6885	8100	0,520	11,28 €
QTR31307	35	80	22,8	21	25	60	65	6503	7650	0,520	14,00 €
QTR32307	35	80	32,8	31	25	93	103	6885	8100	0,730	15,39 €

Dimensions in mm

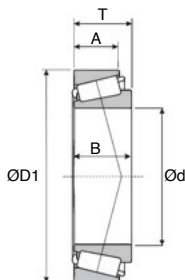

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List -10%	-15%	-20%	On request	

Part number	Ød	ØD1	T	B	A	Load (kN)		Load (rpm)		Weight (kg)	Price each 1 to 5
						Dynamic (C)	Static (Co)	lubricant Grease	Oil		
QTR32008	40	68	19,0	19	14,5	51	69	7268	8550	0,270	10,05 €
QTR33108	40	75	26,0	26	20,5	77	101	6885	8100	0,510	14,90 €
QTR30208	40	80	19,8	18	16	60	66	6503	7650	0,420	9,51 €
QTR32208	40	80	24,8	23	19	77	84	6503	7650	0,530	13,29 €
QTR33208	40	80	32,0	32	25	102	129	6503	7650	0,770	19,14 €
QTR30308	40	90	25,3	23	20	84	93	6120	7200	0,720	12,74 €
QTR31308	40	90	25,3	23	17	83	79	5738	6750	0,720	16,88 €
QTR32308	40	90	35,3	33	27	114	137	6120	7200	1,000	19,92 €
QTR32009	45	75	20,0	20	15,5	57	78	6503	7650	0,340	10,15 €
QTR33109	45	80	26,0	26	20,5	94	111	6120	7200	0,560	22,11 €
QTR30209	45	85	20,8	19	16	64	75	6120	7200	0,480	12,35 €
QTR32209	45	85	24,8	23	19	89	96	6120	7200	0,580	14,71 €
QTR33209	45	85	32,0	32	25	105	140	5738	6750	0,820	20,95 €
QTR30309	45	100	27,3	25	22	105	117	5355	6300	0,970	16,43 €
QTR31309	45	100	27,3	25	18	103	100	5126	6030	0,950	18,30 €
QTR32309	45	100	38,3	36	30	137	166	5355	6300	1,350	22,76 €
QTR32010	50	80	20,0	20	15,5	59	86	6120	7200	0,370	13,97 €
QTR33010	50	80	24,0	24	19	67	100	6120	7200	0,450	16,84 €
QTR33110	50	85	26,0	26	20	84	119	5738	6750	0,590	23,64 €
QTR30210	50	90	21,8	20	17	75	89	5738	6750	0,540	13,83 €
QTR32210	50	90	24,8	23	19	80	98	5738	6750	0,610	15,45 €
QTR33210	50	90	32,0	32	24,5	111	156	5355	6300	0,900	27,61 €
QTR30310	50	110	29,3	27	23	140	137	4820	5670	1,250	19,69 €
QTR31310	50	110	29,3	27	19	119	117	4590	5400	1,200	27,55 €
QTR32310	50	110	42,3	40	33	179	211	4590	5400	1,850	33,24 €
QTR32011	55	90	23,0	23	17,5	79	113	5355	6300	0,550	14,19 €
QTR33011	55	90	27,0	27	21	101	134	5355	6300	0,670	23,80 €
QTR33111	55	95	30,0	30	23	107	152	5126	6030	0,860	32,50 €
QTR30211	55	100	22,8	21	18	101	103	5126	6030	0,700	14,68 €
QTR32211	55	100	26,8	25	21	103	126	5126	6030	0,830	19,56 €
QTR33211	55	100	35,0	35	27	135	186	4820	5670	1,200	28,23 €
QTR30311	55	120	31,5	29	25	162	159	4284	5040	1,550	24,64 €
QTR31311	55	120	31,5	29	21	118	134	4284	5040	1,550	30,36 €
QTR32311	55	120	45,5	43	35	211	254	4284	5040	2,500	40,94 €

Dimensions in mm

QTR

Steel

- Especially designed to handle combined axial and radial loads
- A demountable bearing, i.e. the inner ring and roller cage form a single element that can mounted separately from the external ring
- Static and dynamic loads are radial loads
- Materials:
Steel flanges and cylinders
Pressed steel cage




DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	ØD1	T	B	A	Load (kN)		Load (rpm)		Weight (kg)	Price each 1 to 5
						Dynamic (C)	Static (Co)	Lubricant Grease	Oil		
QTR33012	60	95	27,0	27	21	103	140	5126	6030	0,710	24,74 €
QTR33112	60	100	30,0	30	23	114	166	4820	5670	0,920	34,08 €
QTR30212	60	110	23,8	22	19	109	111	4590	5400	0,880	17,46 €
QTR32212	60	110	29,8	28	24	122	156	4590	5400	1,150	21,21 €
QTR33212	60	110	38,0	38	29	164	231	4590	5400	1,600	34,44 €
QTR30312	60	130	33,5	31	26	164	192	4055	4770	1,950	31,33 €
QTR31312	60	130	33,5	31	22	142	162	4055	4770	1,900	33,83 €
QTR32312	60	130	48,5	46	37	224	284	4055	4770	2,850	42,65 €
QTR32013	65	100	23,0	23	17,5	94	124	4590	5400	0,630	20,69 €
QTR33013	65	100	27,0	27	21	107	149	4820	5670	0,780	25,97 €
QTR33113	65	110	34,0	34	26,5	139	203	4284	5040	1,300	37,51 €
QTR30213	65	120	24,8	23	20	129	131	4284	5040	1,150	23,02 €
QTR32213	65	120	32,8	31	27	148	189	4284	5040	1,500	24,06 €
QTR33213	65	120	41,0	41	32	190	264	4055	4770	2,050	43,62 €
QTR30313	65	140	36,0	33	28	190	223	3672	4320	2,400	38,03 €
QTR31313	65	140	36,0	48	39	161	189	3672	4320	2,350	41,65 €
QTR32313	65	140	51,0	37	29	241	338	3456	4320	3,450	54,98 €
QTR32014	70	110	25,0	25	19	99	149	4284	5040	0,840	25,42 €
QTR33014	70	110	31,0	31	25,5	127	192	4284	5040	1,100	27,26 €
QTR33114	70	120	37,0	37	29	168	245	4055	4770	1,700	41,26 €
QTR30214	70	125	26,3	24	21	122	152	4055	4770	1,250	25,90 €
QTR32214	70	125	33,3	31	27	153	203	4055	4770	1,600	28,20 €
QTR33214	70	125	41,0	41	32	197	279	3825	4500	2,100	46,57 €
QTR30314	70	150	38,0	35	30	215	254	3443	4050	2,900	47,41 €
QTR31314	70	150	38,0	35	25	183	215	3443	4050	2,950	49,48 €
QTR32314	70	150	54,0	51	42	291	372	3443	4050	4,300	72,64 €

Dimensions in mm

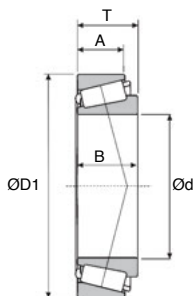

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	ØD1	T	B	A	Load (kN)		Load (rpm)		Weight (kg)	Price each 1 to 5
						Dynamic (C)	Static (Co)	Grease	Oil		
QTR32015	75	115	25,0	25	19	103	159	4055	4770	0,900	27,58 €
QTR33015	75	115	31,0	31	25,5	131	223	4055	4770	1,150	47,18 €
QTR33115	75	125	37,0	37	29	172	259	3825	4500	1,800	43,53 €
QTR30215	75	130	27,3	25	22	137	172	3825	4500	1,400	28,43 €
QTR32215	75	130	33,3	31	27	157	207	3825	4500	1,700	33,92 €
QTR33215	75	130	41,0	41	31	204	294	3672	4320	2,250	47,47 €
QTR30315	75	160	40,0	37	31	241	284	3290	3870	3,450	63,55 €
QTR31315	75	160	40,0	37	26	204	240	3290	3870	3,500	67,07 €
QTR32016	80	125	29,0	29	22	135	211	3825	4500	1,300	32,01 €
QTR33016	80	125	36,0	36	29,5	164	279	3825	4500	1,650	51,93 €
QTR33116	80	130	37,0	37	29	175	274	3672	4320	1,900	50,25 €
QTR30216	80	140	28,3	26	22	148	179	3672	4320	1,600	37,38 €
QTR32216	80	140	35,3	33	28	183	240	3443	4050	2,050	40,55 €
QTR33216	80	140	46,0	46	35	246	367	3443	4050	2,900	56,69 €
QTR30316	80	170	42,5	39	33	264	313	3290	3870	4,100	66,68 €
QTR31316	80	170	42,5	39	27	219	259	3060	3600	4,050	135,28 €
QTR32316	80	170	61,5	58	48	372	490	3290	3870	6,200	101,68 €
QTR32017	85	130	29,0	29	22	137	219	3672	4320	1,350	39,78 €
QTR33017	85	130	36,0	36	29,5	179	303	3672	4320	1,750	57,24 €
QTR33117	85	140	41,0	41	32	215	333	3443	4050	2,450	55,42 €
QTR30217	85	150	30,5	28	24	172	215	3290	3870	2,050	40,39 €
QTR32217	85	150	38,5	36	30	207	279	3290	3870	2,600	50,71 €
QTR33217	85	150	49,0	49	37	280	421	3290	3870	3,700	70,25 €
QTR30317	85	180	44,5	41	34	296	357	3060	3600	4,850	69,11 €
QTR32018	90	140	32,0	32	24	164	264	3290	3870	1,750	45,63 €
QTR33018	90	140	39,0	39	32,5	211	347	3443	4050	2,200	70,88 €
QTR33118	90	150	45,0	45	35	246	382	3290	3870	3,100	67,98 €
QTR32218	90	160	42,5	40	34	246	333	3060	3600	3,350	57,43 €
QTR30318	90	190	46,5	43	36	323	392	3060	3600	5,650	109,47 €
QTR31318	90	190	46,5	43	30	258	308	2601	3060	5,900	207,17 €
QTR32318	90	190	67,5	64	53	447	597	3060	3600	8,400	164,04 €

Dimensions in mm

Altri prodotti...



NSA

Connettore rinvio d'angolo, Articolato



ZHBRA

Ingranaggio conico in plastica, 1,25:1 2:1 3:1



BOX-SHNA

Dado esagonale - DIN934, Valigetta di dadi acciaio




PTA100

Piede snodato con base stampata Ø100, 15000N



TCXR

Tenditore per catena automatico, Con pignone inox

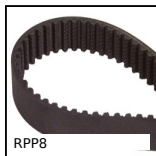

RPP8

Cinghia di trasmissione RPP, RPP8



ZY

Piedino antivibrante cilindrico, Inox



BCH_SS

Pomello a fungo inox, M3 a M8



DOG11

Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm



ZY

Piedino antivibrante cilindrico, Inox



ACLCHAR


Cerniera ad avvitare, Con fori oblunghi



DOG319

Motoriduttore DC 12V e 24V DC, da 4 a 9 Nm

Prodotti correlati

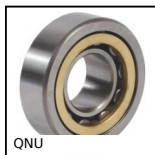


QNU

Cuscinetto a singola corona di rulli cilindrici, Anello interno libero



Q1

Cuscinetto orientabile a sfere, Acciaio

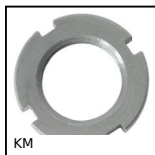

KM

Cuscinetti a sfere - Accessorio, Ghiera KM



EAR

Cuscinetti a sfere - Accessorio, Ghiera autobloccante - anello di fr...