


- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

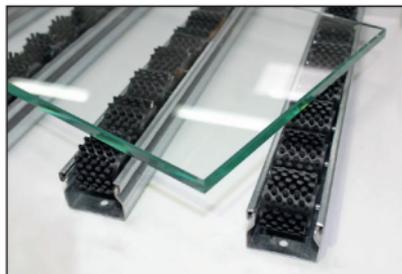

Typical application

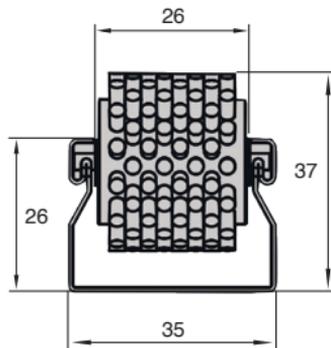

DISCOUNTS

Qty	1+	2+	5+	10+	20+
Disc. List	-5%	-11%	-14%	On request	

Part number	Length L (mm)	Space between rollers (mm)	Nb of rollers	Load-bearing capacity per 1 m track (kg)	Price each.
Low density					
RAG-B30-2000	2000	66	30	25	
High density					
RAG-B60-2000	2000	33	60	50	

Dimension in mm

Altri prodotti...



COA-COG

Staffa di montaggio per molla a gas, Staffa di montaggio piana per s...




ZG1

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



PRF_GAL

Rotella per profilo alluminio, Rotella liscia

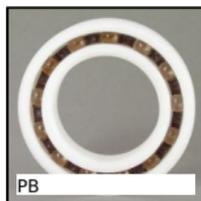

PB

Cuscinetto in plastica, Plastica - materiale sfere : vetro



HCSS

Grano con punta a coppa, punta a coppa



RBGtc

Ruota girevole a foro centrale, Acciaio - gomma grigia



DOG316

Motoriduttore DC 12V e 24V DC, da 1.5 a 2 Nm



SCA_SS

Serracavo, Inox



UCFL

Cuscinetto a flangia ovale in ghisa, Ghisa



PRF19_E

Squadra di giunzione, PRF19 a PRF32



CHAFR-MINI

Cerniera, A frizione



GMK17_BR

Morsetto porta guide, Conico doppio

Prodotti correlati



RAGFLOW

Rotaia a rulli Floway2®, Rotaia a rulli



RAGFLOWsupport

Accessori per rotaia a rulli Floway2®, Roller track support



RAG

Guida di scorrimento a rullini,