



- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

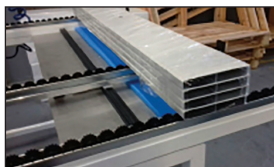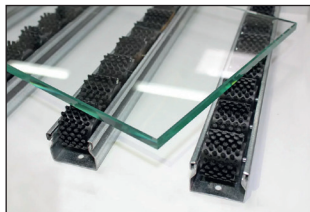

Typical application

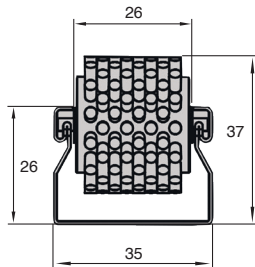


DISCOUNTS

Qty	1+	2+	5+	10+	20+
Disc.	List	-5%	-11%	-14%	On request

Part number	Length L (mm)	Space between rollers (mm)	Nb of rollers	Load-bearing capacity per 1 m track (kg)	Price each.
Low density					
RAG-B30-2000	2000	66	30	25	
High density					
RAG-B60-2000	2000	33	60	50	

Dimension in mm

Altri prodotti...

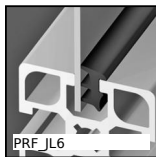

Panel accessories,
Guarnizione - Ø 6mm




Accessori di
collegamento, Piastra



Ingranaggio conico in
plastica stampata, 1:1



Vite a ricircolo di
sfere, Supporto

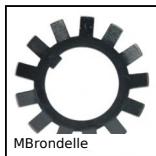


Cuscinetti a sfere -
Accessorio, Rondella
di arresto MB



Rinvio angolare ad
albero cavo, fino a 30
Nm



Adjustable furniture
foot, square tube

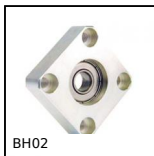

Cuscinetto radiale
flangiato, Montaggio
con circlips

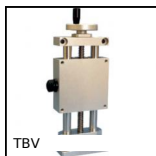


Tavola di
posizionamento



Ingranaggio dritto di
precisione, Acciaio



Tenditore per catena
automatico, Con



Tubo quadrato,
Alluminio

Prodotti correlati