



- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

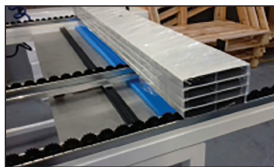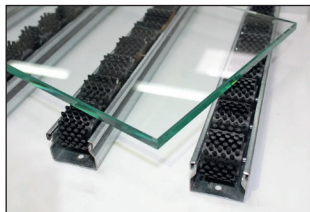

Typical application

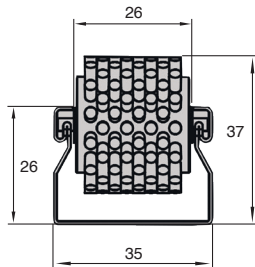

DISCOUNTS

Qty	1+	2+	5+	10+	20+
Disc. List	-5%	-11%	-14%	On request	

Part number	Length L (mm)	Space between rollers (mm)	Nb of rollers	Load-bearing capacity per 1 m track (kg)	Price each.
Low density					
RAG-B30-2000	2000	66	30	25	
High density					
RAG-B60-2000	2000	33	60	50	

Dimension in mm

Altri prodotti...



T5-10ECO

Puleggia dentata di posizionamento tipo T, Serie economica - T5 allu...



BABA

Perno autobloccante, Acciaio



CHB

Feet, For CHB gearbox



NPTF30

Morsetto di collegamento, Fisso Ø14 a Ø20



PRSS0

Piede snodato tutto inox Ø50, Ø 50



HLC28

Rinvio angolare a dentatura spiroidale, Fino a 182Nm




SMS

Ingranaggio conico spiroidale, 1:1



YG1

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6

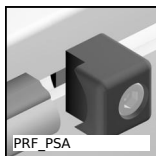


PRF_PSA

Rotella per profilo alluminio, per bloccaggio albero



CHC

Vite a testa cava esagonale CHC, Acciaio classe 12.19

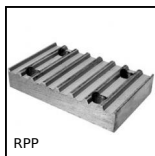

RPP

Piastra di giunzione per cinghia RPP, RPP14



BC3

Panamech, Multi-Beam inox, Inox - con ganaschia di serraggio

Prodotti correlati



RAGFLOW

Rotai a rulli Floway2®, Rotai a rulli



RAGFLOWsupport

Accessori per rotaia a rulli Floway2®, Roller track support



RAG

Guida di scorrimento a rullini,