



- Mini roller conveyor prevents damage to parts
- Surface-friendly fibre arrangement
- Dirt adhesion is prevented
- Reduced manual effort
- Easy handling in all direction

Materials


- Plastic roller, polyamide fibres
- Steel rail

Advantages

- Ideal for sensitive products
- Quiet conveying

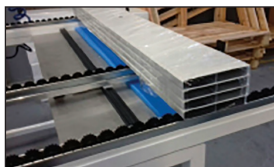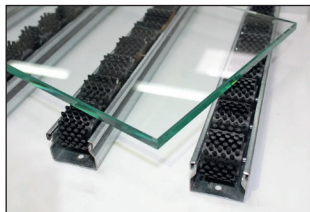

Typical application

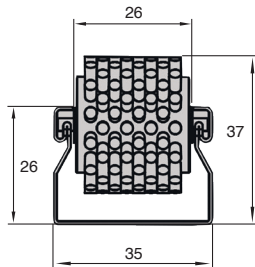

DISCOUNTS

Qty	1+	2+	5+	10+	20+
Disc. List	-5%	-11%	-14%	On request	

Part number	Length L (mm)	Space between rollers (mm)	Nb of rollers	Load-bearing capacity per 1 m track (kg)	Price each.
Low density					
RAG-B30-2000	2000	66	30	25	
High density					
RAG-B60-2000	2000	33	60	50	

Dimension in mm

Altri prodotti...



HLA24

Rinvio angolare a dentatura spiroidale, Fino a 78Nm



PCS37K

Pignone a catena dentatura temprata, 9.525mm (DIN06B-1)



BOX-TOR-C

Valigetta di guarnizioni toriche in nitrile, 3.00 x 1.50mm a 30.20 x...



PM4

Ruota per vite senza fine, Bronzo



BABPass

Perno autobloccante inox temprato ad anello, Con impugnatura ad



SSE

Snodo sferico inox, Inox/PTFE



HW_HT

Guida su semi-binari, Ruota



MC

Deceleratore, autocompensante - senza regolazione



SVR5

Martinetto a vite - Vite rotante, Con madrevite esterna



HTD5M_15

Puleggia dentata di trasmissione tipo HTD, HTD5 Acciaio



SBF

Sealed flange bearing unit for Food Industry, cover



AT10-50ECO

Puleggia dentata di posizionamento tipo AT, Serie economica - AT10 a...

Prodotti correlati



RAGFLOW

Rotaaia a rulli Floway2®, Rotaaia a rulli



RAGFLOWsupport

Accessori per rotaaia a rulli Floway2®, Roller track support



RAG

Guida di scorrimento a rullini,