

Manual bevel gearbox



RAM30

Manual torque up to 4 Nm




- **Manually operated bevel gearbox**
- Ratios from 1:1
- **Materials:**
 - Housing: Glass fibre reinforced PA6
 - Bevel gears: Case hardened steel

Accessories


- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

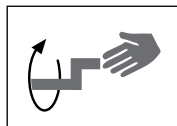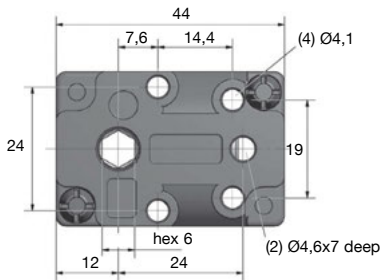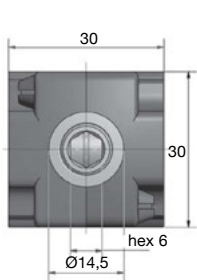

For manual applications

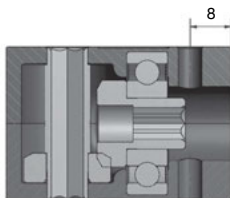

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM30-1	1:1	hex 6mm	hex 6mm	4	38,52 €

Dimensions in mm

Altri prodotti...



CNA-CNG

Staffa di montaggio per molla a gas, Staffa di montaggio a squadra p...




PSG15

Ingranaggio dritto di precisione, Inox 303



RPCplss

Ruota girevole con piastra, Inox - Poliammide

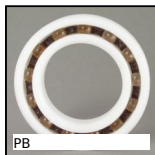

PB

Cuscinetto in plastica, Plastica - materiale sfere : vetro



SHN

Dado esagonale - DIN934, Acciaio (Class 6[8])



MDB_MTB

Ingranaggio conico in plastica stampata, 2:1



BTE

Tenditore automatico universale, Per applicazioni correnti



CHA1056-U4

Cerniera ad avvitare, Aperura 180°



CHTRP

Riduttore a rinvio angolare a L o a T, fino a 34,5 Nm



DOMI80

Slitta di regolazione Domino 80, Slitta DOMILINE 80



MBF

Manicotto filettato di bloccaggio, Montaggio e regolazione rapidi



MDB_MTB

Ingranaggio conico in plastica stampata, 3:1

Prodotti correlati



AHX

Riduttore manuale, Barra esagonale



MBEX

Riduttore manuale, Manovella estremità esagonale