



Manual bevel gearbox

Manual torque up to 6 Nm

RAM35





- **Manually operated bevel gearbox**
- Ratios from 1:1 to 2:1
- Materials:
Housing: Glass fibre reinforced PA6
Bevel gears: Case hardened steel

Accessories

- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

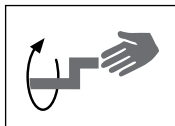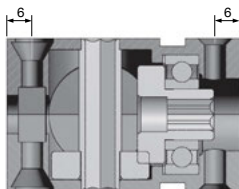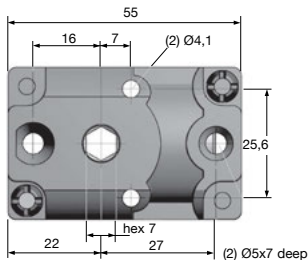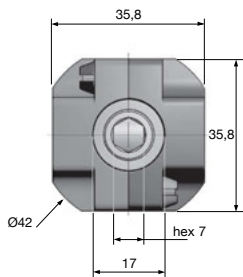

For manual applications

DISCOUNTS

| Qty | 1+ | 10+ | 25+ | 50+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -15% | On request |

| Part number | Ratio | Input | Output | Max torque (Nm) | Price each 1 to 9 |
|-------------|-------|---------|---------|-----------------|-------------------|
| RAM35-1 | 1:1 | hex 7mm | hex 7mm | 6 | 49,85 € |
| RAM35-2 | 2:1 | hex 7mm | hex 7mm | 6 | 49,85 € |

Dimensions in mm

Altri prodotti...



PDD

Pressore a molla
sensore di
rilevamento, Con asta
di comando per int...



BEF

Vite a ricircolo di sfere
miniatura, Supporto
con cuscinetto



ACL-PLAngle

Elementi di giunzione,
Collegamento
angolare



PP50

Riduttore a ruota e
vite senza fine, da
6.50 a 12.80 Nm



BEK

Vite a ricircolo di sfere
miniatura, Supporto



AT5-16ECO

Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT5 al...



WJUM10

Pattino Drylin® W,
Pattino




FBL6000_K1

Spazzola al metro
fibre PA6 da Ø0,2 a
Ø0,3, Poliammide
nero 6 - pi...




RPCpl

Ruota girevole con
piastra, Acciaio -
Poliammide

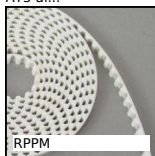

RPPM

Cinghia aperta al
metro tipo RPP, RPP14
Poliuretano armatura

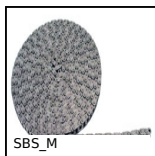

SBS_M

Catena semplice al
metro, Inox



MAX22

Motoriduttore DC 12V
e 24V DC, da 0,07 a
0,2Nm

Prodotti correlati



AHEX

Riduttore manuale,
Barra esagonale



MBEX

Riduttore manuale,
Manovella estremità
esagonale