



Manual bevel gearbox

Manual torque up to 6 Nm

RAM35





- **Manually operated bevel gearbox**
- Ratios from 1:1 to 2:1
- Materials:
Housing: Glass fibre reinforced PA6
Bevel gears: Case hardened steel

Accessories

- MBEX handle
- AHEX hexagonal shaft

Info

- Not suitable for motorised applications

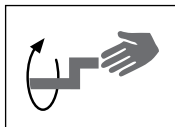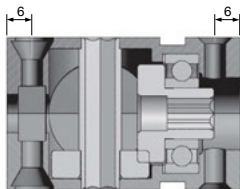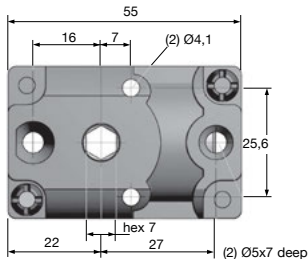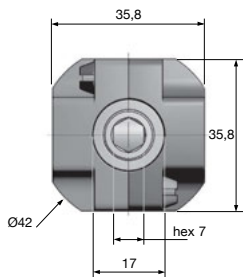

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input	Output	Max torque (Nm)	Price each 1 to 9
RAM35-1	1:1	hex 7mm	hex 7mm	6	49,85 €
RAM35-2	2:1	hex 7mm	hex 7mm	6	49,85 €

Dimensions in mm

Altri prodotti...



SLB

Pistoncino a molla,
acciaio classe 5.8



HLUT

Volantino con razze e
impugnatura girevole,
Alluminio



PM2

Coppia ruota e vite
senza fine, Plastica
lavorata (delrin)



DFG

Ventosa, silicone



CHA_GC_9SS

Cerniera (tutto inox),
A saldare




GP

Chiusura a leva molla
a trazione
compensata, Con
porta-lucchetto




GGP

Vite ad alette,
Tecnopolimero con
inserto in acciaio

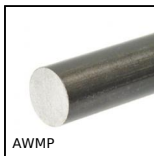

AWMP

Albero in alluminio
per guida lineare,
Alluminio

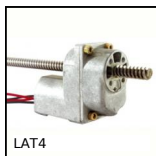

LAT4

Attuatore lineare a
motore 4A, 4 ampere



G3

Ingranaggio dritto
acciaio, Acciaio
20NCD2



PITAss

Pistoncino a molla,
con maniglia a T



AT5-25ECO

Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT5 al...

Prodotti correlati



AHEX

Riduttore manuale,
Barra esagonale



MBEX

Riduttore manuale,
Manovella estremità
esagonale