

Blue EPDM sealing washer

Hygienic Usit®

RDE-BHUSS

- Sealing washer for Hygienic Usit® screws
- Flat metal gasket with elastomer bead for cavity-free, static sealing of screwed connections.
- Material:
 - Stainless steel 1.4404 (316L)
 - Rubber seal: 75 Fluoroprene XP 45, blue

Advantages

- The sealing washer ensures there is no risk of any cavities within a screwed connection.
- Residues or cleaning liquids cannot settle unnoticed thus avoiding any contamination by germs or bacteria.

Use.

- Even if, when tightening the screw connection, the elastomer bead cannot be overloaded by the integrated stainless-steel washer, any material will arrive sooner or later at the end of useable life. Fragments could then be found in foodstuffs.
- The sealing materials used and the colours used make it easy to detect these unwanted elements.


Applications

- For special requirements, such as very greasy and corrosive liquids or very high temperatures, which can occur for example, during cleaning operations.



Warning

- The Hygienic Usit washer cannot guarantee a cavity-free watertight screwed connection unless it is used with screws or nuts from the Hygienic Usit® range.

For hostile environments

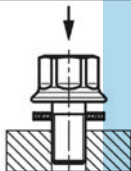

Cavity free seal

 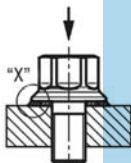

REMISES

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD1	S	For hexagonal nut	Price each
					1 to 4
RDE-4B/HUSS	4,2	9,7	1	M3/M4	10,55 €
RDE-5B/HUSS	5,2	10,7	1	M5	10,42 €
RDE-6B/HUSS	6,2	13,1	1	M6	10,95 €
RDE-8B/HUSS	8,2	16,9	1	M8	14,00 €
RDE-10B/HUSS	10,2	21,2	1,5	M10	16,21 €
RDE-12B/HUSS	12,2	25,5	1,5	M12	16,80 €
RDE-16B/HUSS	16,2	33,9	1,5	M16	25,50 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

39

Altri prodotti...



DOMI30
Accessori di collegamento, Kit di fissaggio




PDD
Pressore a molla sensore di rilevamento, Con asta di comando per int...



PLA
Magnete, Magnete piatto con filettatura



CHA1056_U20
Cerniera ad avvitare, Sezione 90X60

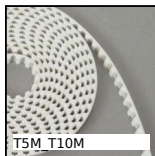

T5M T10M
Cinghia aperta al metro tipo T, T5 Poliuretano armatura in acciaio



CMA
Vite ad occhiello, Acciaio



NCT
Giunto di collegamento, Ad angolo fisso



NT92
Riduttore coassiale a treni paralleli, da 15 a 40 Nm - a treni paral...



PHT
Maniglia a ponte, Fino a 250°C



M1
Coppia ruota e vite senza fine, Acciaio non temprato



J64
Riduttore coassiale a treni paralleli, da 0.57 a 2.25 Nm - a treni



HLC28
Rinvio angolare a dentatura spiroidale, Fino a 182Nm

Prodotti correlati



CLAT
Maniglia a ripresa Hygienic Usit®, Inox



CLA
Maniglia a ripresa Hygienic Usit®, Inox



BCTH
Pomello a fungo Hygienic Usit®, Con foro filettato e collare alto



BCFH
Pomello a fungo Hygienic Usit®, Con perno filettato e collare alto