

- Rigging screw with 1 welded clevis and 1 manually tightened end


- Material: 316 stainless steel

### Advantages

- Quick and easy fixing on the end of a cable  
(For mounting method, refer to ERF/SS page)



**NEW!**

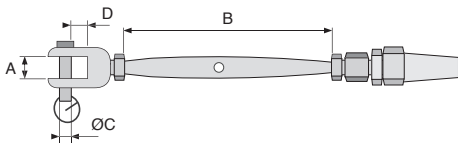

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	For cable ØD1	A	B	ØC	D	Weight (g)	Price each 1 to 5
RDER3-5/SS	3	10	80,0	5	8	68	45,44 €
RDER3-6/SS	3	8	92,0	6	8,5	106	50,37 €
RDER4-6/SS	4	8	92,0	6	8,5	124	57,28 €
RDER4-8/SS	4	10	112,0	8	11	202	65,09 €
RDER5-8/SS	5	10	112,0	8	11	224	83,82 €
RDER5-10/SS	5	11,5	120,0	10	12	330	94,06 €
RDER6-10/SS	6	11,5	120,0	10	12	362	98,86 €
RDER6-12/SS	6	14	150,0	12	16	560	143,66 €

Dimensions in mm

## Altri prodotti...



PRF4545

Profilato alluminio standard, 45 x 45 mm



BMM

Manopola, zigrinata



AC

Piastrina di riscontro, 12mm



SLB

Pistoncino a molla, acciaio classe 5.8



PSG125S

Ingranaggio dritto di precisione, Inox 303



WJUM10

Pattino Drylin® W, Pattino



BSPM

Vite a ricircolo di sfere miniatura, Dado + vite a ricircolo di sfere



CTss

Giunto cardanico telescopico inox, Sollecitazioni leggere



PO

Maniglia a ponte - Multi-settore, Foro



TSM\_T10M

Cinghia aperta al metro tipo T, T5



PCH

Impugnatura, Fungo



BG

Giunto Oldham, con vite a pressione

## Prodotti correlati




ERF

Terminale rapido per cavi, Terminale filettato



RDCss

Tenditore, Inox

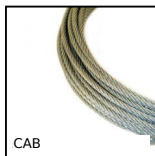

CAB

Cavo di fissaggio, Inox



ERC

Terminale rapido per cavi, A forcella