


- **Ideal gearbox for use in the food industry**
- Ratios from 50:1 to 300:1
- 3-stage reduction
- B14 or B5 flange
- Rounded and polished surfaces to avoid material retention
- Lubricated using food quality grease
- 90% efficient
- Material:
316 stainless steel housing

Accessories

- Can be used with a DER 4-pole motor to create a motor-gearbox
- Torque arms, mounting bracket and protective cover

Info

- All information is engraved directly on to gearbox rather than being on a tag plate to avoid accumulating dirt etc.

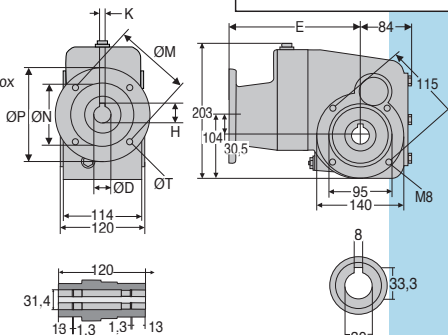

Output shaft

Flange dimensions

	ØD	K	H	ØP	ØM	ØN	E	ØT
Flange 63B5	11	4	12,8	140	115	95	178,8	9
Flange 71B14	14	5	16,3	105	85	70	185,8	6,5
Flange 80B14	19	6	21,8	120	100	80	205,8	6,5

DISCOUNTS

Qty	1+	2+	4+
Rem.	Net	-5%	On request

Part N°			Nominal reduction ratio	Actual reduction ratio	Price each
Bride 63B5	Bride 71B14	Bride 80B14			
	RFK48C-50-71B14/SS	RFK48C-50-80B14/SS	50	49,18	1 618,24 €
	RFK48C-60-71B14/SS	RFK48C-60-80B14/SS	60	62,43	1 618,24 €
RFK48C-75-63B5/SS	RFK48C-75-71B14/SS	RFK48C-75-80B14/SS	75	75,45	1 618,24 €
RFK48C-100-63B5/SS	RFK48C-100-71B14/SS	RFK48C-100-80B14/SS	100	99,22	1 618,24 €
RFK48C-125-63B5/SS	RFK48C-125-71B14/SS	RFK48C-125-80B14/SS	125	125,95	1 618,24 €
RFK48C-150-63B5/SS	RFK48C-150-71B14/SS	RFK48C-150-80B14/SS	150	151,2	1 618,24 €
RFK48C-200-63B5/SS	RFK48C-200-71B14/SS		200	200,66	1 618,24 €
RFK48C-250-63B5/SS	RFK48C-250-71B14/SS		250	240,89	1 618,24 €
RFK48C-300-63B5/SS	RFK48C-300-71B14/SS		300	297,21	1 618,24 €

Altri prodotti...



UGH32
Unità di guida tipo H,
Per martinetti Ø 32



SCA
Serracavo, Acciaio



PM4
Ruota per vite senza
fine, Bronzo



BLH70
Rinvio angolare a L,
da 26 a 128 Nm



BSM
Pressore a molla con
esagono incassato,
corpo e spina inox
303



NK40
Guida mini Drylin® N,
Larghezza 40 mm



NAST
Rotelle, Con anello
interno



PDR-RD
Piede con ruota
integrata, Ruota
disassata



GP
Chiusura a leva molla
a trazione
compensata,



PSG125
Ingranaggio dritto di
precisione, Acciaio
35NCD6 pretrattato



CQA20
Slitta di regolazione
miniatura, 20



PTA50ssEB
Piede snodato con
base stampata Ø50,
4000N

Prodotti correlati



DER63
Motore inox AC
asincrono 0,18kW,
0.18kW



DER71
Motore inox AC
asincrono da 0,25 a
0,37kW, 0.25 a
0.37kW



DER80
Motore inox AC
asincrono da 0,55 a
0,75kW, 0.55 a
0.75kW



RFKfp
Riduttore inox -
accessori, Piede di
supporto