



Locking castor with mounting plate

For loads up to 1000kg

RIM

 

- A combination of a swivel castor and an adjustable locking support
- Used to easily support and moving machines or other heavy equipment and then positioning them in a very stable manner.
- Installation starts by lowering the locking support using a nut.
- With the wheel no longer resting on the ground, the supported unit can be levelled despite any irregularities in the floor.
- Operating temperature range: -30 to +80°C



Adjusting nut

Materials

- Polyamide central control cross nut
- Anti-skid rubber mount allowing absorption of vibration and noise
- Body: Moulded cast aluminium body, hammered ivory paint finish
- Swivel system provided by 2 ball rings
- Mounting plate has a threaded central hole, threaded rod and nut supplied.
- Wheel: Black polyamide Shore D 70

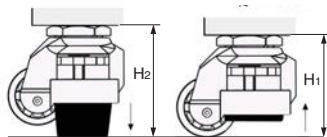

DISCOUNTS

Qty	1+	5+	14+
Disc.	List	-5%	On request

Part number	ØA	B	H1	H2	L	M	ØT	Swivel interference ØK	Load (kg)	Price each 1 to 5
RIM42-60/PLE	42	20	71	81	55x55	42x42	6,5	84	60	44.77 €
RIM50-280/PLE	50	25	82	92	73x73	58x58	7	101	280	71.10 €
RIM63-550/PLE	63	28	103	118	90x90	70x70	9	125	550	96.62 €
RIM75-800/PLE	75	30	120	132	95x95	70x70	11	142	800	106.81 €
RIM75-1000/PLE	75	30	120	132	95x95	70x70	11	142	1000	127.36 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

283

Altri prodotti...



YG3

Ingranaggio dritto
PRESTAZIONE, Acciaio
35NCD6



RJA00_02

Guarnizione in
gomma, Da
agganciare



T5P_T10P

Piastra di giunzione
per cinghia T, T10



PRF_P

Elementi di
ancoraggio, Base di
ancoraggio



AT10courroie

Cinghia di
posizionamento AT,
AT10 Poliuretano
armatura in acciaio



AC

Piastrina di riscontro,
12,13,18 e 20mm



PTBss

Bullone a occhiello
inox, Inox




CHB

Riduttore a ruota e
vite senza fine, fino a
22 Nm



CHB

Riduttore a ruota e
vite senza fine, fino a
73 Nm

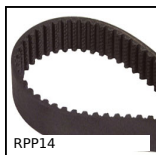

RPP14

Cinghia di
trasmissione RPP,
RPP14



CHB

Braccio di reazione,
Braccio di reazione
per riduttori CHB



DHX

Spina cilindrica filetto
interno, estraibile DIN
7979D

Prodotti correlati



RIMtce

Ruota di livellamento,
Con foro centrale



PDR-RD

Piede con ruota
integrata, Ruota
disassata