

Polyamide wheel

For loads up to 600kg

RPC

- Light coloured Polyamide wheel
- Smooth central bore
- Working temperature range: -30°C to +80°C

Advantages

- Shock and abrasion resistant
- Does not stain floors
- Does not mark floors
- Resists most chemical agents
- Low rolling resistance
- For solid and hard floors
- Ideal for use in wet and dirty environments (fish markets, butcher shops, canneries)



For smooth surfaces



ØD



B



C



ØA

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	B	C	ØA	Maximum load (kg)	Stock*	Price each 1 to 9
RPC60-31/ML	60	31	40	12	200	✓	2,06 €
RPC80-32/ML	80	32	40	12	250	✓	2,14 €
RPC100-32/ML	100	32	40	12	300	✓	2,83 €
RPC100-35/ML	100	35	48	15	350	-	9,76 €
RPC125-36/ML	125	36	50	15	350	-	5,16 €
RPC125-41/ML	125	41	59	20	400	-	10,93 €
RPC150-37/ML	150	37	49	15	400	-	8,19 €
RPC160-40/ML	160	40	58	20	500	-	22,48 €
RPC200-50/ML	200	50	58	20	600	-	24,41 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

265

Altri prodotti...



PRF_CLIP_45

Clip di fissaggio per
cavi per profili
alluminio, Per
canalina di ca...



EHD04

Riduttore coassiale,
da 3.4 a 7 Nm



BSM

Pressore a molla con
esagono incassato,
corpo e spina inox
303



SDG_SS

Supporto con tirante
ad occhio, Inox



BABT

Perno autobloccante,
Inox temprato



T5P_T10P

Piastra di giunzione
per cinghia T, T10



AT10-50ECO

Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT10 a...




PPS

Anello di
sollevamento, Gancio
universale ad avvitare



GP

Chiusura a leva molla
a trazione

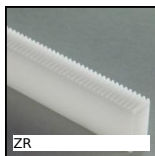

ZR

Cremagliera in
plastica, Delrin



KSM

Dado cilindrico in
acciaio, Acciaio - 1



SSBRA

Ingranaggio conico
inox, 1:1

Prodotti correlati



RPCpl

Ruota fissa con
piastra, Acciaio -
Poliammide



RPCpl

Ruota girevole con
piastra, Acciaio -
Poliammide



RPCpl

Ruota girevole a
doppio bloccaggio,
Acciaio - poliammide



RPCplss

Ruota girevole con
piastra, Inox -
Poliammide