

Connecting plate

PITCH
RPP5
RPP8
RPP14

For open belts RPP5M, RPP8M
 and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material : aluminium

Applications


- For closing an open belt
- To attach an open belt to a structure

Accessories

- RPP../P belts
- HTD pulleys

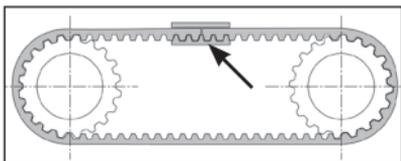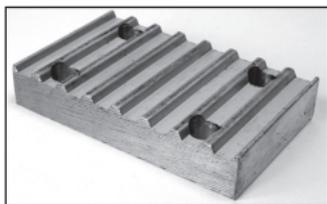

Typical application

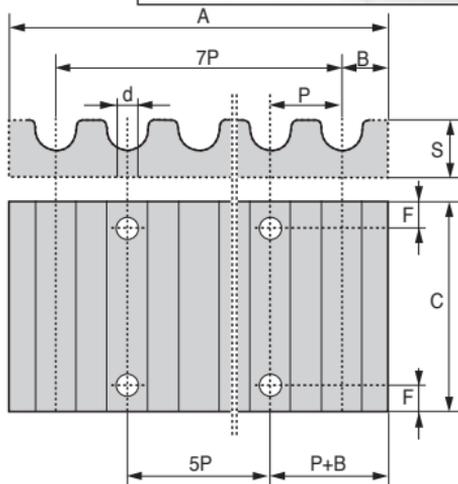

DISCOUNTS

Qty.	1+	6+	20+
Disc.	List -10%		On request

Part number	Pitch	F	d	B	A	S	C	Belt width	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	10,82 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	13,21 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	36,26 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	41,68 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	55,34 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	141,06 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	185,51 €

Dimensions in mm

Altri prodotti...



SSG1_304L
Ingranaggio dritto
Inox, Inox 304L



NK40
Guida mini Drylin® N,
Larghezza 40 mm



BH01
Cuscinetto radiale
flangiato, Montaggio :
pressione e colla



PCLA_T
Maniglia a ripresa,
Plastica



QN
Cuscinetto a singola
corona di rulli
cilindrici, Anello
esterno libero



GE
Chiusura a leva,
Standard



PITA
Pistoncino a molla,
con maniglia a T



M1
Vite senza fine ,
Acciaio temprato



PR125
Piede fissabile con
snodo - poliammide, Ø
123



FF15
Riduttore ad alberi
paralleli, da 2.20 a 10
Nm




GSI_A
Vite di regolazione
per molla a gas, Vite di
regolazione



MEFC
Cuscinetto a collare ,
Lega di ferro FP20
autolubrificante
METAFRAM

Prodotti correlati

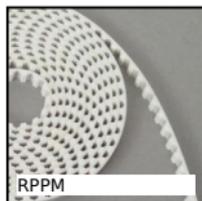

RPPM
Cinghia aperta al
metro tipo RPP, RPP8
Poliuretano armatura
in acciaio