

Connecting plate

PITCH
RPP5
RPP8
RPP14

For open belts RPP5M, RPP8M
 and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material : aluminium

Applications


- For closing an open belt
- To attach an open belt to a structure

Accessories

- RPP../P belts
- HTD pulleys

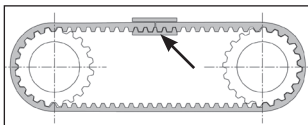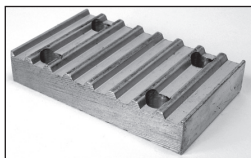

Typical application

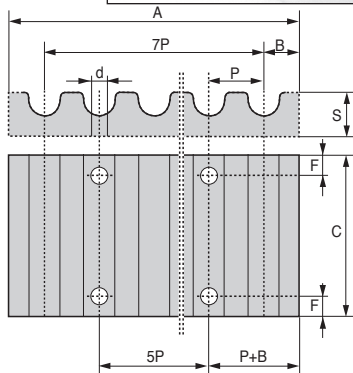

DISCOUNTS

Qty.	1+	6+	20+
Disc.	List -10%		On request

Part number	Pitch	F	d	B	A	S	C	Belt width	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	10,82 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	13,21 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	36,26 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	41,68 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	55,34 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	141,06 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	185,51 €

Dimensions in mm

Altri prodotti...



Spazzola al metro fibre PA6 da Ø0,3 a Ø0,5, Poliammide nero 6 - me...



Spazzola strip, Lunghezza 3m



Magnete, Con foro maschiato



Guida lineare a sfere - Sfere inox, Carello - da 514 N a 16700 N



Inserto con piastrina a incollare Masterplate®, Cilindrico Ø23 con...



Rinvio angolare a dentatura spiroidale, Fino a 78Nm



Chiusura a leva con serratura, Riscontro grezzo



Guida lineare Utilitrack®, Profilo guida a V



Ingran. dritto di precisione trattato skiving, Acciaio



Catena a tapparella, Larga serie 882




Riduttore coassiale, da 8 a 19 Nm



Ingranaggio conico in plastica stampata , 1.5:1

Prodotti correlati

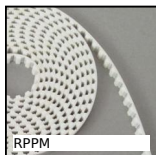

Cinghia aperta al metro tipo RPP, RPP8 Poliuretano armatura in acciaio