

Connecting plate

PITCH
RPP5
RPP8
RPP14

For open belts RPP5M, RPP8M
 and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material : aluminium

Applications


- For closing an open belt
- To attach an open belt to a structure

Accessories

- RPP../P belts
- HTD pulleys

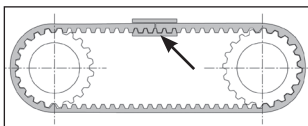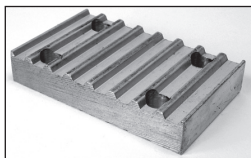

Typical application

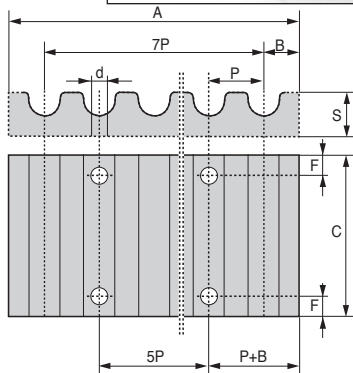

DISCOUNTS

Qty.	1+	6+	20+
Disc.	List -10%		On request

Part number	Pitch	F	d	B	A	S	C	Belt width	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	10,82 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	13,21 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	36,26 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	41,68 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	55,34 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	141,06 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	185,51 €

Dimensions in mm

Altri prodotti...



VEL
Rotolo a strappo
fermacavi, cavi
elettrici e pneumatici



T5M T10M
Cinghia aperta al
metro tipo T, T5
Poliuretano armatura
in acciaio



CCLSS
Capocorda ad
occhiello, Inox



DBL880
Rotella per catena,
Serie 880 e 881



SFWR
Supporto per
estremità dell'albero,
Elemento a muro




RAM30
Riduttore manuale,
Rinvio angolare



GAC
Chiusura a leva con
serratura, Bloccabile



PGB
Attrezzi, Porta attrezzi

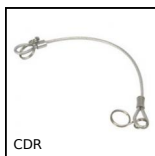

CDR
Per perno
autobloccante, Cavo
di ritegno



BCFH
Pomello a fungo
Hygienic Usit®, Con
perno filettato e
collare alto




PLM-C
Magnete piatto di
fermo, Magnete di
fermo piatto



TK_UUOP
Manicotto a sfere
autoallineante
Topball,
Autoallineante Topball

Prodotti correlati

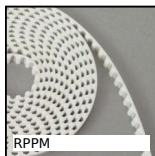

RPPM
Cinghia aperta al
metro tipo RPP, RPP8
Poliuretano armatura
in acciaio