

# Connecting plate

**PITCH**  
**RPP5**  
**RPP8**  
**RPP14**

For open belts RPP5M, RPP8M  
 and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material : aluminium

## Applications


- For closing an open belt
- To attach an open belt to a structure

## Accessories

- RPP../P belts
- HTD pulleys

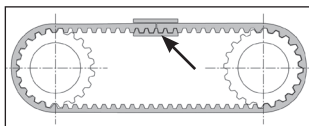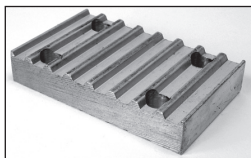

Typical application

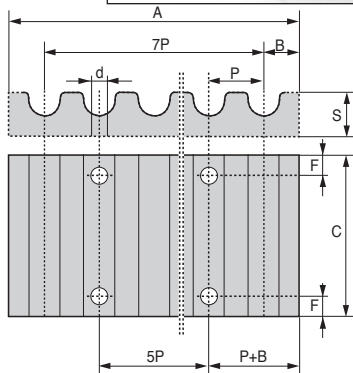

## DISCOUNTS

Qty.	1+	6+	20+
Disc.	List -10%		On request

Part number	Pitch	F	d	B	A	S	C	Belt width	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	10,82 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	13,21 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	36,26 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	41,68 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	55,34 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	141,06 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	185,51 €

Dimensions in mm

## Altri prodotti...



SEH

Attrezzo di bloccaggio a tirante, A tirante - acciaio



UGPL

Unità di guida per cilindrico, Cuscinetto lungo



KB\_WW

Manicotto chiuso a sfere di precisione, Economica



HW\_HT

Guida su semi-binari, Ruota



PW\_PWG3

Vite senza fine di precisione, Inox



BMM

Manopola, zigrinata



WW16

Carrello Drylin® W, Carrello



DER80

Motore inox AC asincrono da 0,55 a 0,75kW, 0.55 a 0.75kW



NSO

Supporto standard per manicotto aperto a



PENV

Maniglia da incasso, Ad avvitare



DOG319


Motoriduttore DC 12V e 24V DC, da 4 a 9



EHD12

Riduttore coassiale, da 60 a 140 Nm

## Prodotti correlati

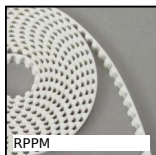

RPPM

Cinghia aperta al metro tipo RPP, RPP14  
Poliuretano armatura in acci...