

Connecting plate

PITCH
RPP5
RPP8
RPP14

For open belts RPP5M, RPP8M
 and RPP14M



- 5mm, 8mm and 14mm pitches
- For linear movements
- Rigid connecting plates
- Material : aluminium

Applications


- For closing an open belt
- To attach an open belt to a structure

Accessories

- RPP../P belts
- HTD pulleys

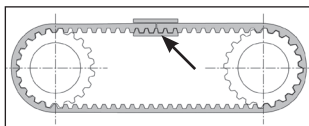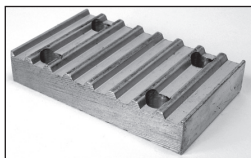

Typical application

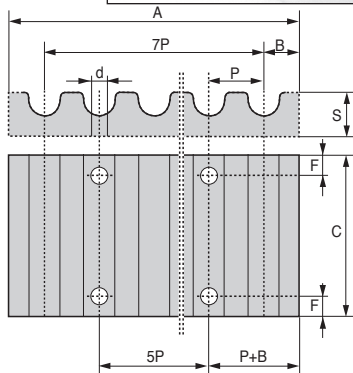

DISCOUNTS

Qty.	1+	6+	20+
Disc.	List -10%		On request

Part number	Pitch	F	d	B	A	S	C	Belt width	Price each 1 to 5
RPP5/15P	RPP5	6	5,5	3,25	41,5	8	34	15	10,82 €
RPP5/25P	RPP5	6	5,5	3,25	41,5	8	44	25	13,21 €
RPP8/20P	RPP8	8	9,0	5,00	66,0	15	45	20	36,26 €
RPP8/30P	RPP8	8	9,0	5,00	66,0	15	55	30	41,68 €
RPP8/50P	RPP8	8	9,0	5,00	66,0	15	75	50	55,34 €
RPP14/55P	RPP14	10	11,0	9,00	116,0	22	86	55	141,06 €
RPP14/85P	RPP14	10	11,0	9,00	116,0	22	116	85	185,51 €

Dimensions in mm

Altri prodotti...



HDSS
Giunto cardanico -
inox, Sollecitazioni
intense



M2
Coppia ruota e vite
senza fine, Plastica
lavorata (delrin)




PFC
Piede fisso,
Livellamento per
piccoli elementi



VPPTss
Volantino pieno con
impugnatura girevole,
Inox 304



AC156-157
Riscontro per chiusura
a leva rigida ad
anello, 25.5mm

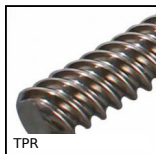

TPR
Madrevite a passo
lungo, Madrevite sola-
fino a 40mm di corsa
per rot...



SLS
Supporto per vite
trapezoidale,
Supporto Drylin®
frottante




BOX-TOR-D
Valigetta di
guarnizioni toriche in
nitrile, 18.00 x
2.00mm a 50.00 ...



GPLbr
Scovolo, ottone



MET
Cuscinetto cilindrico ,
Self-lubricating
sintered bronze

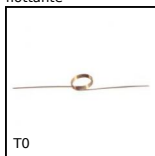


TO
Molla di torsione, Inox



VTSM
Ball head screws
Hygienic Design®,
Inox

Prodotti correlati

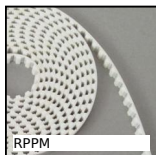

RPPM
Cinghia aperta al
metro tipo RPP, RPP14
Poliuretano armatura
in acci...