

# RPP type belt by **the metre**



## Pitch

## Polyurethane with steel core

# RPP5

# RPP8

# RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

### Applications


- Reciprocating movements

### Accessories



- RPP.../P connecting plates
- HTD pulleys

### Info.

- Minimum length 1000mm
- Supplied in multiples of 1 metre
- When ordering, add the length (L) and width (I) to the part number (**RPP5M/L/I**)
- E.g. : **RPP5M/1000/15**

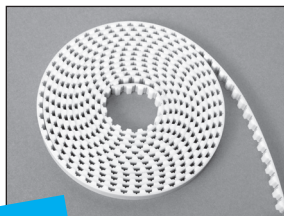

**For linear positioning**

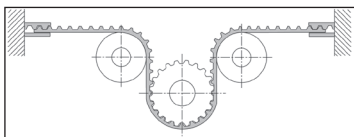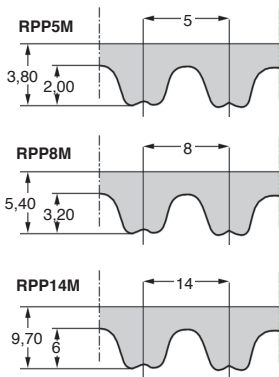

Typical application

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

## Altri prodotti...



STRIP  
Spazzola strip,  
Lunghezza 3m



SBS\_L  
Giunzione per catena  
al metro, Maglia di  
giunzione - inox



PRF\_ECL  
Fissaggio, Dado  
quadrato con  
linguetta - Acciaio



MDB\_MTB  
Ingranaggio conico in  
plastica stampata, 2:1



CHAK  
Cerniera, Hi-Klik™ - di  
posizionamento




CHA1056-UPA  
Cerniera su facciata in  
poliammide,  
Poliammide nera



DOG316  
Motoriduttore DC 12V  
e 24V DC, da 1.5 a 2  
Nm



GALRUB  
Rullo per  
trasportatore, Caucciù

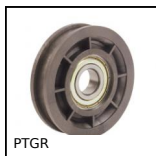

PTGR  
Puleggia folle, Per  
cinghia tonda



CABPVC  
Cavo acciaio  
galvanizzato con PVC  
trasparente, Acciaio




GLP  
Volantino a 6 lobi,  
Tecnopolimero -  
Acciaio



ZG0  
Ingranaggio dritto in  
plastica, Plastica  
lavorata (delrin)

## Prodotti correlati

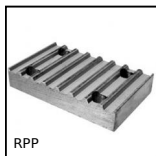

RPP  
Piastra di giunzione  
per cinghia RPP,  
RPP14