

RPP type belt by **the metre**



Pitch

Polyurethane with steel core

RPP5

RPP8

RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

Applications


- Reciprocating movements

Accessories



- RPP.../P connecting plates
- HTD pulleys

Info.

- Minimum length 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and width (I) to the part number (RPP5M/L/I)
- E.g. : RPP5M/1000/15

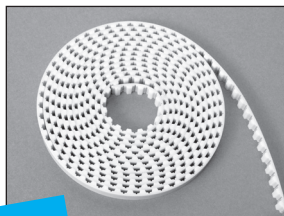

For linear positioning

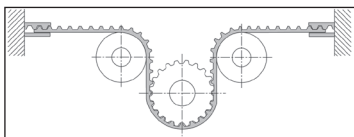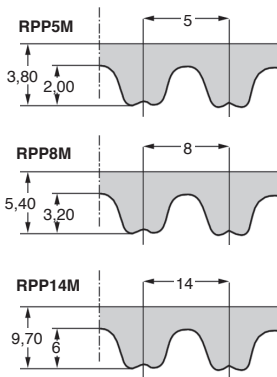

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

Altri prodotti...



AT5P_AT10P

Piastra di giunzione
per cinghia AT, AT10



WSRM

Dado cilindrico in
polimero, Polimero
(Iglidur®) - 1 filetto



SSB

Ingranaggio conico
inox, 1:1



CHAGC-AL

Cerniera ad avvitare,
Sfilabile



TMR

Tenditore rigido,
Manuale



DGSI

Testa a snodo
femmina, Acciaio /
acciaio - Serie
economica




MEP

Impugnatura cilindrica
libera, Fissa



SFE

Testa a snodo
femmina, Inox / PTFE

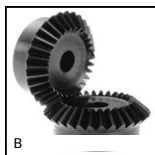

B

Ingranaggio conico -
Acciaio 60C40, 1:1



BPM-Z

Pressore a molla con
intaglio e puntale a
sfera, Corpo plastica
+ sf...



TRMSS

Cremagliera a sezione
circolare, Inox -
modulo 1-5



BOX-TOR-MAX

Valigetta di
guarnizioni toriche in
nitrile, 2.90 x 1.78mm
a 82.14 x...

Prodotti correlati



RPP

Piastra di giunzione
per cinghia RPP, RPP8