

RPP type belt by **the metre**



Pitch

Polyurethane with steel core

RPP5

RPP8

RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

Applications


- Reciprocating movements

Accessories



- RPP.../P connecting plates
- HTD pulleys

Info.

- Minimum length 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and width (I) to the part number (RPP5M/L/I)
- E.g. : RPP5M/1000/15

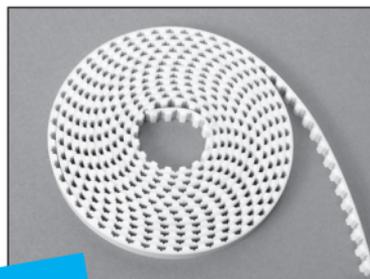

For linear positioning

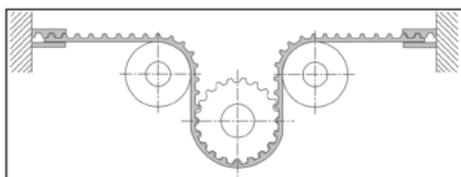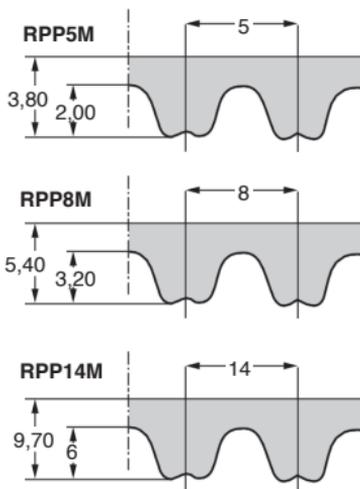

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

Altri prodotti...




APBC
Supporto per sensore,
Tubo di collegamento
per morsetto



PRFRTR
Elementi di giunzione,
Giunto di
collegamento
trasversale



CLB_T
Maniglia a ripresa -
maschio, Zamak

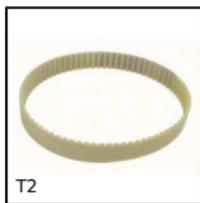

T2
Cinghia di
posizionamento T,
T2.5 Poliuretano
armatura in acciaio



SVR15
Martinetto a vite - Vite
rotante, Con
madrevite esterna



M1
Vite senza fine,
Acciaio temprato



SSB
Ingranaggio conico
inox, 1:1



CHM75
Riduttore a ruota e
vite senza fine, fino a
298 Nm



BPL
Sfera portante con
flangia, Leggero



TPEf
Ruota per profili
alluminio, Fissa




GPB
Impugnatura sferica,
Con inserto ottone



GE32
Chiusura a leva rigida
ad anello, Standard

Prodotti correlati

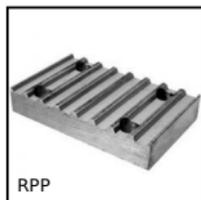

RPP
Piastra di giunzione
per cinghia RPP,
RPP14