

RPP type belt by **the metre**



Pitch

Polyurethane with steel core

RPP5

RPP8

RPP14

- For linear movements
- 5mm, 8mm and 14mm pitches
- Fixed using rigid connecting plate

Applications


- Reciprocating movements

Accessories



- RPP.../P connecting plates
- HTD pulleys

Info.

- Minimum length 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and width (I) to the part number (RPP5M/L/I)
- E.g. : RPP5M/1000/15

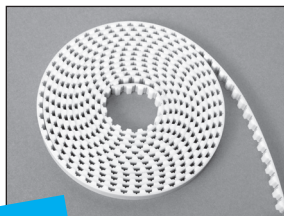

For linear positioning

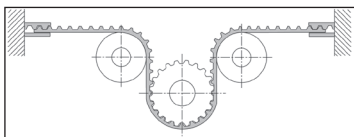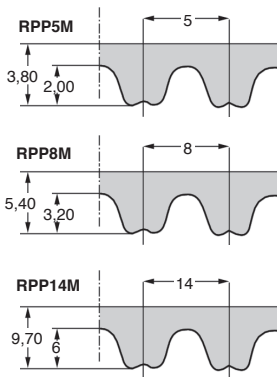

Typical application

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Pitch	Price each 1 to 5 per metre for widths of						
		15mm	20mm	25mm	30mm	50mm	55mm	85mm
RPP5M	RPP5	14,06 €	-	25,78 €	-	-	-	-
RPP8M	RPP8	-	22,51 €	-	29,90 €	35,70 €	-	-
RPP14M	RPP14	-	-	-	-	-	62,80 €	103,83 €

Dimensions in mm

Altri prodotti...



PAP

Maniglia e battuta per porta, Maniglia ergonomica




G1

Ingranaggio dritto acciaio, Acciaio 20NCD2



PFC

Piede fisso, Livellamento per piccoli elementi

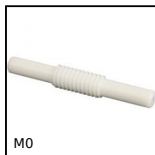

M0

Coppia ruota e vite senza fine, Plastica lavorata (delrin)



BUH77

Motoriduttore DC 12V e 24V DC, da 0.1 a 2 Nm



BDPR

Braccio di reazione, Rigido



PTMC

Telescopico furniture foot, square plate



CLG1

Ingranaggio dritto in plastica stampata, Nylon stampato



BS3

Panamech, Multi-Beam inox, Inox - con



UFX

Giunto elastico UNEFLEX, range



MFBC

Giunto a soffietto, Alluminio e bronzo -



SF_ZZ

Cuscinetto radiale a sfere, Inox

Prodotti correlati



RPP

Piastra di giunzione per cinghia RPP, RPP14