

# Free running wheel with mounting plate

For loads up to 350kg

RURP

- Light industrial castor for loads up to 350kg
- Materials:
  - Top bracket/plate: Plated steel sheet
  - Polyurethane covered wheel 85 Shore
  - Aluminium rim
- Swivel castor with double locks: simple to lock/unlock using foot operated pedal
- Hub with ball bearing
- Working temperature range: -30 to +80°C

Swivel with double lock




## Advantages

- Smooth and quiet running
- Resists wear
- Very strong
- Recommended for its exceptional resistance and its long-term service
- Low risk of flat spots developing if the wheel is not used

For rough floors

## Applications

- Rough floors
- Can be used where metal chips, solvents, oil or grease is present

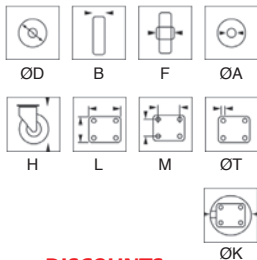

## DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Références	ØD	H	B	A	F	L	M	ØT	Swivel inter-farence	Max load (kg)	Price each 1 to 9
<b>Swivel</b>											
RURP80/P	80	110	40	12	41	110x85	80x60	8	162	180	26,87 €
RURP100/P	100	127	40	12	41	110x85	80x60	8	184	220	29,51 €
RURP125/P	125	155	40	15	41	110x85	80x60	8	216	260	33,17 €
RURP150/P	150	181	40	20	50	110x85	80x60	8	244	350	42,85 €
<b>Swivel with double brake</b>											
RURP80/PDB	80	110	40	12	41	110x85	80x60	8	290	180	30,91 €
RURP100/PDB	100	127	40	12	41	110x85	80x60	8	290	220	33,76 €
RURP125/PDB	125	155	40	15	41	110x85	80x60	8	290	260	37,79 €
RURP150/PDB	150	181	40	20	50	110x85	80x60	8	290	350	47,31 €
<b>Fixed</b>											
RURP80/F	80	110	40	12	41	110x85	80x60	8	-	180	23,73 €
RURP100/F	100	127	40	12	41	110x85	80x60	8	-	220	26,21 €
RURP125/F	125	155	40	15	41	110x85	80x60	8	-	260	30,25 €
RURP150/F	150	181	40	20	50	110x85	80x60	8	-	350	40,35 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Altri prodotti...




CHA\_GC\_95S  
Cerniera a bandiera  
inox, A saldare



FF20  
Riduttore ad alberi  
paralleli, da 5.80 a 23  
Nm



BOXKU  
Box kit di chiavette a  
disco, Box kit di  
chiavette a disco -  
acciaio

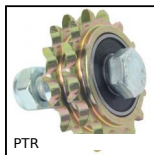

PTR  
Pignone tendicatenena,  
Per applicazioni  
correnti



CHT  
Motore AC asincrono  
trifase, 1.1 a 1.85kW



PF70  
Riduttore a ruota e  
vite senza fine, fino a  
164 Nm



BSM\_LOK  
Pressore a molla con  
esagono incassato,  
LONG-LOK - corpo e  
spina in ...




NT121  
Riduttore coassiale a  
treni paralleli, da 20 a  
68 Nm - a treni  
paral...



DILC  
Indexing plunger with  
cam, with cam



HW\_HT  
Guida su semi-binari,  
Ruota

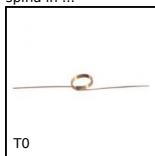

TO  
Molla di torsione, Inox



PGT  
Accessori per  
pannello, Profilo per  
pannello scorrevole

## Prodotti correlati



RUR  
Ruota, Poliuretano -  
Mozzo alluminio (Ultra  
scorrevole)



RPCpl  
Ruota girevole con  
piastra, Acciaio -  
Poliammide



RBNpl  
Ruota girevole con  
piastra, Acciaio -  
caucciù



RURp  
Ruota fissa con  
piastra, Poliuretano -  
Mozzo alluminio (Ultra  
scorrevole)