

Manual worm wheel gearbox



RVM14

Manual torque up to 5 Nm



- **Manually operated bevel gearbox**
- Ratios from 1:1 to 23:1
- **Materials:**
 - Housing: Zamak
 - Worm wheel: Case hardened steel

Accessories

- MBEX handle
- AHEx hexagonal shaft

Info

- Not suitable for motorised applications

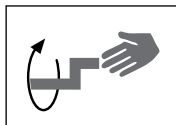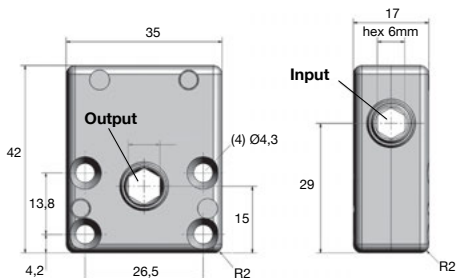

For manual applications

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Ratio	Input/Output	Max torque (Nm)	Self locking	Price each 1 to 9
RVM14-1	1:1	hex 6mm	2,0	No	76,99 €
RVM14-2	2:1	hex 6mm	2,0	No	76,99 €
RVM14-2.8	2,8:1	hex 6mm	2,5	No	76,99 €
RVM14-4.33	4,33:1	hex 6mm	2,0	Yes	76,99 €
RVM14-10	10:1	hex 6mm	4,0	Yes	76,99 €
RVM14-14	14:1	hex 6mm	5,0	Yes	76,99 €
RVM14-15	15:1	hex 6mm	4,0	Yes	76,99 €
RVM14-23	23:1	hex 6mm	3,0	Yes	76,99 €

Dimensions in mm

Altri prodotti...



VB

Volantino a 6 lobi,
Duroplast - Ottone



FF15

Riduttore ad alberi
paralleli, da 2.20 a 10
Nm



PSG125

Ingranaggio dritto di
precisione, Acciaio
35NCD6 pretrattato



COA-COG

Staffa di montaggio
per molla a gas,
Staffa di montaggio
piana per s...



OP7

Indicatore di posizione
digitale (N. di giri), 5
cifre




PTR

Pignone tendicatena,
Per applicazioni
correnti



AXTR

Puleggia folle, Perno

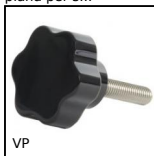


VP

Volantino a 6 lobi,
Duroplast - Acciaio



MDR_SS

Grillo con chiodo ad
occhiello, Inox

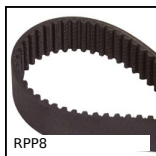

RPP8

Cinghia di
trasmissione RPP,
RPP8



GE

Chiusura a leva,
Standard



PTA100

Piede snodato con
base stampata Ø100,
Ø 100

Prodotti correlati



AHEX

Riduttore manuale,
Barra esagonale



MBEX

Riduttore manuale,
Manovella estremità
esagonale