



# Manually operated gearbox

Manual torque up to 17 Nm

RVM25



- Compact manually operated gearbox
- Ratios from 1:1 to 30:1
- Material:  
Housing: Zamak

## Accessories

- MBEX handle
- AHX hexagonal shaft

## Info

- Not suitable for motorised applications

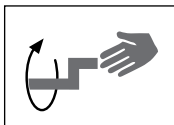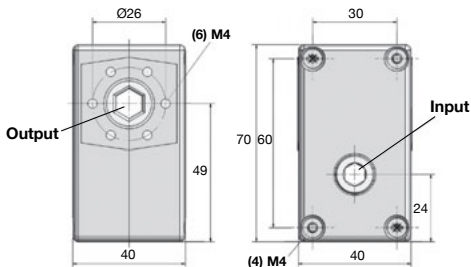

For manual applications

## DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request


Part number	Ratio	Input	Output	Max torque (Nm)	Self locking	Price each 1 to 9
RVM25-1	1:1	hex 6mm	hex 9mm	2,0	No	113,30 €
RVM25-2	2:1	hex 6mm	hex 9mm	3,0	No	113,30 €
RVM25-3.25	3,25:1	hex 6mm	hex 9mm	4,0	Yes	113,30 €
RVM25-4.33	4,33:1	hex 6mm	hex 9mm	5,0	Yes	113,30 €
RVM25-7	7:1	hex 6mm	hex 9mm	7,0	Yes	113,30 €
RVM25-8.5	8,5:1	hex 6mm	hex 9mm	9,0	Yes	113,30 €
RVM25-17	17:1	hex 6mm	hex 9mm	12,0	Yes	113,30 €
RVM25-20	20:1	hex 6mm	hex 9mm	15,0	Yes	113,30 €
RVM25-30	30:1	hex 6mm	hex 9mm	17,0	Yes	113,30 €

Dimensions in mm

## Altri prodotti...



GMK17\_BR  
Morsetto porta guide,  
Conico singolo

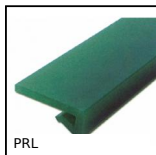

PRL  
Profilo supporto per  
catena, Profilo ad L ad  
incastro



SH0  
Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



IBJ  
Snodo angolare a  
180°, Acciaio



CFUURSS  
Perno folle inox,  
Standard - inox



PENV  
Maniglia da incasso,  
Ad avvitare



EKONSL  
Piedino antivibrante  
conico silicone,  
Fissaggio femmina



INS\_SS  
Inserto auto-filettante,  
Inox 316



GCB880  
Guida curva, Serie  
880 e 881



NT92  
Riduttore coassiale a  
treni paralleli, da 15 a  
70 Nm



BLHB60  
Rinvio angolare, fino a  
70 Nm



BOX-INS-W  
Inserto autofilettante,  
Box kit - Per legno

## Prodotti correlati



AHX  
Riduttore manuale,  
Barra esagonale



MBEX  
Riduttore manuale,  
Manovella estremità  
esagonale