
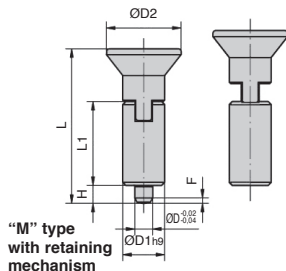


- Manual indexing button, smooth body , no flange
- Two versions available.
- Material :
  - Body: Stainless steel 303
  - Pin: Hardened stainless steel 420
  - Head: Dark grey thermosetting plastic

### Info.

- Index bolts are used where lateral movement is required to be blocked. Pulling the handle releases the pin. With the M version, the pin can be held in the retained position.
- Bolts should be welded using a WIG inert gas process

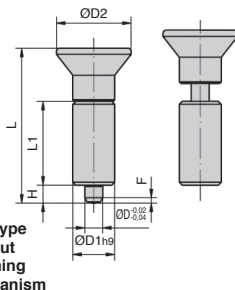

### DISCOUNTS

Qty.	1+	6+	20+
Disc.	List -10% On request		

Part number	ØD	ØD1	ØD2	L	L1	H	Fx30°	Spring force		Price each 1 to 5
								Initial (N)	Final (N)	
SLBW10-L/SS	4	10	18	38,5	21	4	1,0	6	12	12,62 €
SLBW10-M/SS	4	10	18	38,5	21	4	1,0	6	12	15,86 €
SLBW12-L/SS	5	12	21	43,5	24	5	1,3	5	12	11,78 €
SLBW12-M/SS	5	12	21	43,5	24	5	1,3	5	12	15,10 €
SLBW14-L/SS	6	14	25	51,7	28	6	1,8	6	14	13,41 €
SLBW14-M/SS	6	14	25	51,7	28	6	1,8	6	14	17,22 €
SLBW18-L/SS	8	18	33	68,0	36	8	2,3	15	35	17,81 €
SLBW18-M/SS	8	18	33	68,0	36	8	2,3	15	35	21,03 €
SLBW22-L/SS	10	22	33	74,0	40	10	2,8	15	40	28,17 €
SLBW22-M/SS	10	22	33	74,0	40	10	2,8	15	40	33,07 €

## Altri prodotti...



GGP

Vite ad alette,  
Tecnopolimero con  
inserto in acciaio



MRA

Maglia rapida, Acciaio



BH02

Cuscinetto radiale  
flangiato, Montaggio  
con circlips



PW\_PWG15

Vite senza fine di  
precisione, Inox



BLHB30

Rinvio angolare ad  
albero cavo, fino a  
4.47 Nm



CHAR6035

Cerniera a molla,  
avvitabile e saldabile




HRV

Sistema di guida su  
binario a V Simple  
Select®, Binario con  
carrello



H0

Ingranaggio elicoidale  
ad assi incrociati a  
90°, Acciaio 20NCD2

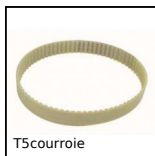

T5courroie

Cinghia di  
posizionamento T, T5  
Poliuretano armatura



VBFP

Volantino a 6 lobi -  
boccola passante,  
Duroplast - Ottone



MFBS

Giunto a soffietto  
Inox, Inox - con  
ganascia di serraggio



M0

Coppia ruota e vite  
senza fine, Acciaio  
non temprato

## Prodotti correlati



SLBW

Pistoncino a molla, Da  
saldare - Acciaio



BIMSS

Pistoncino a molla,  
Miniatura inox