

# Floor mounting levelling plate



## SPIT

## Maximum load 40.000N

- Levelling support for attaching to a floor

- Materials:

Base: galvanised steel



Rod: galvanised steel (nut not supplied)

### Advantages

- Capable of accepting heavy loads.

### Option

- In stainless steel or other dimension if important quantity

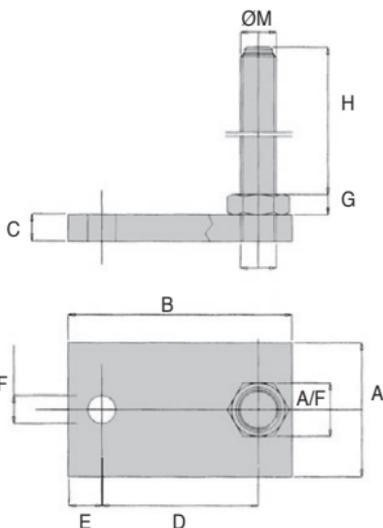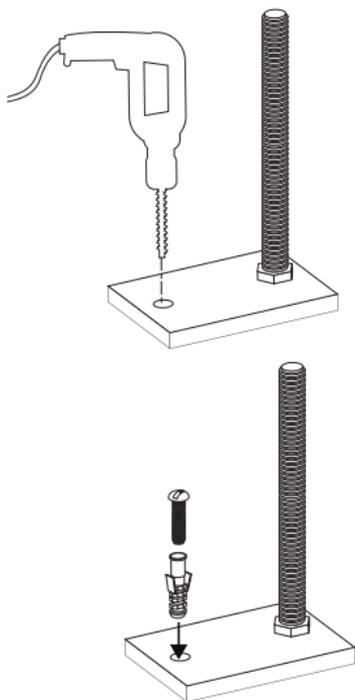

### DISCOUNTS

Qty.	1+	25+	50+
Disc.	List -5%	On request	

Part number	A	B	C	ØM	H	D	E	ØF	G	A/F	Max. load(N)	Price each
SPIT16-150	60	100	12	M16	150	70	15	18	9	24	30000	✓ 22,02 €
SPIT20-200	80	110	12	M20	200	80	15	18	9	24	40000	✓ 24,61 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



BLHB40

Rinvio angolare ad albero cavo, fino a 10.3 Nm



VBFP

Volantino a 6 lobi - boccola passante, Duroplast - Ottone



ZG2

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



PFC

Piede fisso, Livellamento per piccoli elementi



PRF\_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



TBD

Tavola di posizionamento a passo inverso manuale, 5kg



Q1

Cuscinetto orientabile a sfere, Acciaio



WJRM

Pattino ibrido Drylin® W, Cuscinetto ibrido



PSG2

Ingranaggio dritto di precisione, Acciaio



CHB

Single output shaft, For CHB gearbox



PRF\_CLIP\_22

Clip di fissaggio per cavi per profili



BABreglable

Perno autobloccante, Regolabile

## Prodotti correlati



PARF80

Piede senza snodo, Piede snodato oscillante fissabile Ø80



PARF110

Piede senza snodo, Piede snodato oscillante fissabile Ø110