

# Floor mounting levelling plate



## SPIT

## Maximum load 40.000N

- Levelling support for attaching to a floor

- Materials:

Base: galvanised steel




Rod: galvanised steel (nut not supplied)

### Advantages

- Capable of accepting heavy loads.

### Option

- In stainless steel or other dimension if important quantity

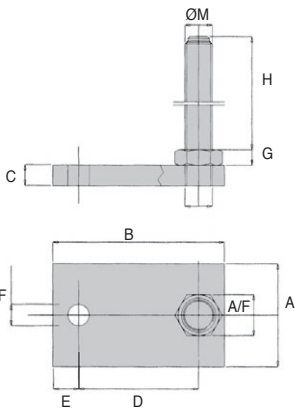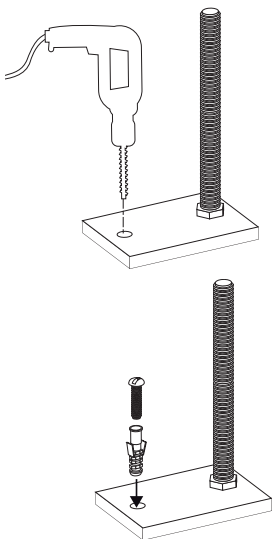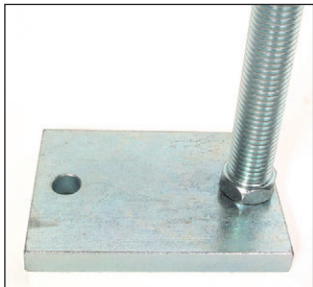

### DISCOUNTS

Qty.	1+	25+	50+
Disc.	List -5%	On request	

Part number	A	B	C	ØM	H	D	E	ØF	G	A/F	Max. load(N)	Stock*	Price each 1 to 24
SPIT16-150	60	100	12	M16	150	70	15	18	9	24	30000	✓	22,02 €
SPIT20-200	80	110	12	M20	200	80	15	18	9	24	40000	✓	24,61 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



RLX  
Rullo folle plastica,  
PVC



SVT5  
Martinetto a vite - Vite  
traslante, Vite  
traslante



CLG1  
Ingranaggio dritto in  
plastica stampata ,  
Nylon stampato



VRSF  
Anello di  
sollevamento,  
Orientabile maschio



GB-RA  
Ingranaggio dritto  
ottone, Ottone  
CuZn39Pb3



ESCON  
Accessori per  
variatore di velocità  
5A, Cavo USB per  
connessione PC



PSG05HC  
Ingran. dritto di  
precisione trattato  
skiving, Acciaio  
20NCD2 cement...



TS01\_TW01  
Guida lineare su  
binario Drylin® T, fino  
al 7000 N



PAP  
Maniglia e battuta per  
porta, Maniglia  
ergonomica



PR40  
Piede fissabile con  
snodo - poliammide, Ø  
40



G0  
Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



PF30  
Riduttore a ruota e  
vite senza fine, fino a  
8.80 Nm

## Prodotti correlati



PARF80  
Piede senza snodo,  
Piede snodato  
oscillante fissabile  
Ø80



PARF110  
Piede senza snodo,  
Piede snodato  
oscillante fissabile  
Ø110