


- For fastening two associated parts
- Stress spread uniformly across width
- Absorbs shocks and vibrations
- For information on shear strength, please see technical information
- Material: stainless steel 304

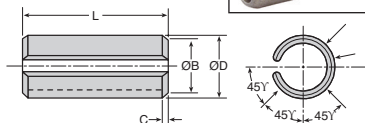

### Info.

- Sold by the packet

### DISCOUNTS

 
N° packets	1+	5+	10+	21+
Disc.	List -10%	-20%		On request

Part number	ØD expanded			L	ØB	Chamfer C	Hole Ø		Qty. per packet	Stock <sup>*</sup>	Price per packet
	Nom. Ø	Min. Ø	Max. Ø				Min.	Max.			
SRP1.5-5/B	1,5	1,70	1,80	5	1,40	0,50	1,50	1,60	100	-	9,99 €
SRP1.5-6/B	1,5	1,70	1,80	6	1,40	0,50	1,50	1,60	100	✓	8,70 €
SRP1.5-8/B	1,5	1,70	1,80	8	1,40	0,50	1,50	1,60	100	✓	9,29 €
SRP1.5-10/B	1,5	1,70	1,80	10	1,40	0,50	1,50	1,60	100	✓	9,46 €
SRP1.5-12/B	1,5	1,70	1,80	12	1,40	0,50	1,50	1,60	100	-	7,75 €
SRP1.5-14/B	1,5	1,70	1,80	14	1,40	0,50	1,50	1,60	100	✓	10,08 €
SRP1.5-16/B	1,5	1,70	1,80	16	1,40	0,50	1,50	1,60	100	-	11,38 €
SRP1.5-18/B	1,5	1,70	1,80	18	1,40	0,50	1,50	1,60	100	-	10,62 €
SRP1.5-20/B	1,5	1,70	1,80	20	1,40	0,50	1,50	1,60	100	✓	12,01 €
SRP2-4/B	2,0	2,30	2,40	4	1,90	0,70	2,00	2,10	100	-	9,86 €
SRP2-5/B	2,0	2,30	2,40	5	1,90	0,70	2,00	2,10	100	✓	9,73 €
SRP2-6/B	2,0	2,30	2,40	6	1,90	0,70	2,00	2,10	100	-	10,08 €
SRP2-8/B	2,0	2,30	2,40	8	1,90	0,70	2,00	2,10	100	✓	8,70 €
SRP2-10/B	2,0	2,30	2,40	10	1,90	0,70	2,00	2,10	100	✓	10,08 €
SRP2-12/B	2,0	2,30	2,40	12	1,90	0,70	2,00	2,10	100	✓	9,46 €
SRP2-14/B	2,0	2,30	2,40	14	1,90	0,70	2,00	2,10	100	✓	10,75 €
SRP2-16/B	2,0	2,30	2,40	16	1,90	0,70	2,00	2,10	100	✓	11,38 €
SRP2-18/B	2,0	2,30	2,40	18	1,90	0,70	2,00	2,10	100	✓	11,69 €
SRP2-20/B	2,0	2,30	2,40	20	1,90	0,70	2,00	2,10	100	✓	12,01 €
SRP2-22/B	2,0	2,30	2,40	22	1,90	0,70	2,00	2,10	100	-	12,37 €
SRP2-24/B	2,0	2,30	2,40	24	1,90	0,70	2,00	2,10	100	✓	13,96 €
SRP2-26/B	2,0	2,30	2,40	26	1,90	0,70	2,00	2,10	100	-	14,53 €
SRP2-30/B	2,0	2,30	2,40	30	1,90	0,70	2,00	2,10	100	✓	16,52 €
SRP2.5-6/B	2,5	2,80	2,90	6	2,40	0,70	2,50	2,60	100	-	8,37 €
SRP2.5-8/B	2,5	2,80	2,90	8	2,40	0,70	2,50	2,60	100	-	10,68 €
SRP2.5-10/B	2,5	2,80	2,90	10	2,40	0,70	2,50	2,60	100	✓	11,08 €
SRP2.5-12/B	2,5	2,80	2,90	12	2,40	0,70	2,50	2,60	100	-	10,22 €
SRP2.5-14/B	2,5	2,80	2,90	14	2,40	0,70	2,50	2,60	100	-	10,57 €
SRP2.5-16/B	2,5	2,80	2,90	16	2,40	0,70	2,50	2,60	100	✓	12,01 €
SRP2.5-18/B	2,5	2,80	2,90	18	2,40	0,70	2,50	2,60	100	-	12,55 €

\*Depending on availability

Part number	ØD expanded				Chamfer			Hole Ø		Qty. per packet	Stock*	Price per packet
	Nom. Ø	Min. Ø	Max. Ø	L	ØB	C	Min.	Max.				
SRP2.5-20/B	2,5	2,80	2,78	20	2,40	0,70	2,49	2,60	100	-	12,90 €	
SRP2.5-22/B	2,5	2,80	2,78	22	2,40	0,70	2,49	2,60	100	-	12,87 €	
SRP2.5-24/B	2,5	2,80	2,78	24	2,40	0,70	2,49	2,60	100	-	15,12 €	
SRP2.5-26/B	2,5	2,80	2,78	26	2,40	0,70	2,49	2,60	100	-	15,23 €	
SRP2.5-30/B	2,5	2,80	2,78	30	2,40	0,70	2,49	2,60	100	✓	14,70 €	
SRP3-5/B	3,0	3,30	3,30	5	2,90	0,90	3,00	3,10	100	-	12,63 €	
SRP3-6/B	3,0	3,30	3,30	6	2,90	0,90	3,00	3,10	100	-	10,75 €	
SRP3-8/B	3,0	3,30	3,30	8	2,90	0,90	3,00	3,10	100	✓	10,08 €	
SRP3-10/B	3,0	3,30	3,30	10	2,90	0,90	3,00	3,10	100	✓	11,38 €	
SRP3-12/B	3,0	3,30	3,30	12	2,90	0,90	3,00	3,10	100	✓	10,75 €	
SRP3-14/B	3,0	3,30	3,30	14	2,90	0,90	3,00	3,10	100	✓	12,55 €	
SRP3-16/B	3,0	3,30	3,30	16	2,90	0,90	3,00	3,10	100	✓	11,59 €	
SRP3-18/B	3,0	3,30	3,30	18	2,90	0,90	3,00	3,10	100	✓	13,34 €	
SRP3-20/B	3,0	3,30	3,30	20	2,90	0,90	3,00	3,10	100	✓	13,82 €	
SRP3-22/B	3,0	3,30	3,30	22	2,90	0,90	3,00	3,10	100	-	13,96 €	
SRP3-24/B	3,0	3,30	3,30	24	2,90	0,90	3,00	3,10	100	✓	15,89 €	
SRP3-26/B	3,0	3,30	3,30	26	2,90	0,90	3,00	3,10	100	-	15,12 €	
SRP3-28/B	3,0	3,30	3,30	28	2,90	0,90	3,00	3,10	100	-	17,15 €	
SRP3-30/B	3,0	3,30	3,30	30	2,90	0,90	3,00	3,10	100	✓	15,89 €	
SRP3-32/B	3,0	3,30	3,30	32	2,90	0,90	3,00	3,10	100	-	16,39 €	
SRP3-35/B	3,0	3,30	3,30	35	2,90	0,90	3,00	3,10	100	-	18,89 €	
SRP3-40/B	3,0	3,30	3,30	40	2,90	0,90	3,00	3,10	100	✓	19,72 €	
SRP4-6/B	4,0	4,40	4,60	6	3,90	1,10	4,00	4,12	100	-	12,01 €	
SRP4-8/B	4,0	4,40	4,60	8	3,90	1,10	4,00	4,12	100	-	13,63 €	
SRP4-10/B	4,0	4,40	4,60	10	3,90	1,10	4,00	4,12	100	✓	15,12 €	
SRP4-12/B	4,0	4,40	4,60	12	3,90	1,10	4,00	4,12	100	✓	15,89 €	
SRP4-14/B	4,0	4,40	4,60	14	3,90	1,10	4,00	4,12	100	-	15,19 €	
SRP4-16/B	4,0	4,40	4,60	16	3,90	1,10	4,00	4,12	100	✓	15,89 €	
SRP4-18/B	4,0	4,40	4,60	18	3,90	1,10	4,00	4,12	100	-	16,52 €	
SRP4-20/B	4,0	4,40	4,60	20	3,90	1,10	4,00	4,12	100	✓	17,15 €	
SRP4-22/B	4,0	4,40	4,60	22	3,90	1,10	4,00	4,12	100	-	17,80 €	
SRP4-24/B	4,0	4,40	4,60	24	3,90	1,10	4,00	4,12	100	✓	18,45 €	
SRP4-26/B	4,0	4,40	4,60	26	3,90	1,10	4,00	4,12	100	-	19,72 €	
SRP4-28/B	4,0	4,40	4,60	28	3,90	1,10	4,00	4,12	100	✓	22,28 €	
SRP4-30/B	4,0	4,40	4,60	30	3,90	1,10	4,00	4,12	100	✓	22,92 €	
SRP4-35/B	4,0	4,40	4,60	35	3,90	1,10	4,00	4,12	50	-	13,53 €	
SRP4-40/B	4,0	4,40	4,60	40	3,90	1,10	4,00	4,12	50	✓	14,50 €	
SRP4-45/B	4,0	4,40	4,60	45	3,90	1,10	4,00	4,12	50	✓	15,48 €	
SRP4-50/B	4,0	4,40	4,60	50	3,90	1,10	4,00	4,12	50	✓	16,77 €	
SRP5-10/B	5,0	5,40	5,60	10	4,85	1,30	5,00	5,12	50	-	9,35 €	
SRP5-12/B	5,0	5,40	5,60	12	4,85	1,30	5,00	5,12	50	-	9,07 €	
SRP5-14/B	5,0	5,40	5,60	14	4,85	1,30	5,00	5,12	50	-	10,57 €	
SRP5-16/B	5,0	5,40	5,60	16	4,85	1,30	5,00	5,12	50	✓	10,36 €	
SRP5-18/B	5,0	5,40	5,60	18	4,85	1,30	5,00	5,12	50	-	11,63 €	
SRP5-20/B	5,0	5,40	5,60	20	4,85	1,30	5,00	5,12	50	✓	13,23 €	
SRP5-22/B	5,0	5,40	5,60	22	4,85	1,30	5,00	5,12	50	-	11,63 €	
SRP5-24/B	5,0	5,40	5,60	24	4,85	1,30	5,00	5,12	50	✓	13,44 €	
SRP5-26/B	5,0	5,40	5,60	26	4,85	1,30	5,00	5,12	50	-	14,61 €	
SRP5-28/B	5,0	5,40	5,60	28	4,85	1,30	5,00	5,12	50	-	14,58 €	
SRP5-30/B	5,0	5,40	5,60	30	4,85	1,30	5,00	5,12	50	✓	12,27 €	

\*Depending on availability



### DISCOUNTS

N° packets	1+	5+	10+	21+
Disc.	List -10%	-20%	-20%	On request

Part number	OD expanded			L	ØB	Chamfer C	Hole Ø		Qty. per packet	Stock <sup>†</sup>	Price per packet
	Nom. Ø	Min. Ø	Max. Ø				Min.	Max.			
SRP5-32/B	5,0	5,40	5,45	32	4,85	1,30	5,00	5,12	50	-	14,19 €
SRP5-35/B	5,0	5,40	5,45	35	4,85	1,30	5,00	5,12	50	✓	13,46 €
SRP5-40/B	5,0	5,40	5,45	40	4,85	1,30	5,00	5,12	50	✓	17,98 €
SRP5-45/B	5,0	5,40	5,45	45	4,85	1,30	5,00	5,12	50	-	19,31 €
SRP5-50/B	5,0	5,40	5,45	50	4,85	1,30	5,00	5,12	50	✓	20,62 €
SRP6-10/B	6,0	6,40	6,70	10	5,85	1,50	6,00	6,12	50	-	11,63 €
SRP6-12/B	6,0	6,40	6,70	12	5,85	1,50	6,00	6,12	50	-	10,66 €
SRP6-14/B	6,0	6,40	6,70	14	5,85	1,50	6,00	6,12	50	-	12,57 €
SRP6-16/B	6,0	6,40	6,70	16	5,85	1,50	6,00	6,12	50	-	13,53 €
SRP6-18/B	6,0	6,40	6,70	18	5,85	1,50	6,00	6,12	50	-	14,50 €
SRP6-20/B	6,0	6,40	6,70	20	5,85	1,50	6,00	6,12	50	✓	15,41 €
SRP6-22/B	6,0	6,40	6,70	22	5,85	1,50	6,00	6,12	50	-	16,09 €
SRP6-24/B	6,0	6,40	6,70	24	5,85	1,50	6,00	6,12	50	-	17,06 €
SRP6-26/B	6,0	6,40	6,70	26	5,85	1,50	6,00	6,12	50	-	16,09 €
SRP6-28/B	6,0	6,40	6,70	28	5,85	1,50	6,00	6,12	50	-	18,66 €
SRP6-30/B	6,0	6,40	6,70	30	5,85	1,50	6,00	6,12	50	✓	19,63 €
SRP6-32/B	6,0	6,40	6,70	32	5,85	1,50	6,00	6,12	50	-	21,55 €
SRP6-35/B	6,0	6,40	6,70	35	5,85	1,50	6,00	6,12	50	-	21,89 €
SRP6-40/B	6,0	6,40	6,70	40	5,85	1,50	6,00	6,12	50	✓	24,13 €
SRP6-45/B	6,0	6,40	6,70	45	5,85	1,50	6,00	6,12	50	-	26,07 €
SRP6-50/B	6,0	6,40	6,70	50	5,85	1,50	6,00	6,12	50	✓	28,31 €
SRP8-10/B	8,0	8,50	8,80	10	7,80	2,00	8,00	8,15	50	-	27,98 €
SRP8-16/B	8,0	8,50	8,80	16	7,80	2,00	8,00	8,15	25	-	8,94 €
SRP8-20/B	8,0	8,50	8,80	20	7,80	2,00	8,00	8,15	25	-	10,72 €
SRP8-22/B	8,0	8,50	8,80	22	7,80	2,00	8,00	8,15	25	-	11,38 €
SRP8-24/B	8,0	8,50	8,80	24	7,80	2,00	8,00	8,15	25	-	11,98 €
SRP8-26/B	8,0	8,50	8,80	26	7,80	2,00	8,00	8,15	25	-	12,63 €
SRP8-28/B	8,0	8,50	8,80	28	7,80	2,00	8,00	8,15	25	-	13,30 €
SRP8-30/B	8,0	8,50	8,80	30	7,80	2,00	8,00	8,15	25	✓	14,09 €
SRP8-35/B	8,0	8,50	8,80	35	7,80	2,00	8,00	8,15	25	-	15,54 €
SRP8-40/B	8,0	8,50	8,80	40	7,80	2,00	8,00	8,15	10	✓	8,40 €
SRP8-50/B	8,0	8,50	8,80	50	7,80	2,00	8,00	8,15	10	✓	9,70 €
SRP10-20/B	10,0	10,50	10,80	20	9,75	2,50	10,00	10,15	10	-	10,94 €
SRP10-24/B	10,0	10,50	10,80	24	9,75	2,50	10,00	10,15	10	-	11,46 €
SRP10-26/B	10,0	10,50	10,80	26	9,75	2,50	10,00	10,15	10	-	11,74 €
SRP10-30/B	10,0	10,50	10,80	30	9,75	2,50	10,00	10,15	10	✓	12,41 €
SRP10-40/B	10,0	10,50	10,80	40	9,75	2,50	10,00	10,15	10	✓	14,05 €
SRP10-50/B	10,0	10,50	10,80	50	9,75	2,50	10,00	10,15	10	✓	15,75 €

<sup>†</sup>Depending on availability

## Altri prodotti...



CHB

Riduttore a ruota e vite senza fine, fino a 41 Nm



GFX

Giunto a dentatura bombata serie economica, Acciaio e poliammide



WTM

Rondella per serraggio - DIN6340, Acciaio



H2

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



WW10

Guida Drylin® W, Carrello



G-ECO2

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



TIFss

Tirante tutto filetto - DIN976A, Inox



VTSM

Ball head screws Hygienic Design®, Inox



CSS

Snodo sferico, acciaio/acciaio autolubrificante



GP75

Chiusura a leva molla a trazione compensata,



RBS

Rondella elastica , Acciaio



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation

## Prodotti correlati



DH

Spina cilindrica, standard DIN 6325



BOXsap

Box kit di spine elastiche ISO8752, Box kit - elastica cilindrica IS...