



# Guidance brush


## Rigid support

## STL


- For guidance and transport
- Easy maintenance
- Materials:  
base: green PVC  
brush: PA6 transparent straight fibres  
rail: galvanised steel

### Advantages


- In case of they need to be replaced, these strip brushes can be quickly removed from the rails
- Their use is recommended in applications where the fibres will be subject to heavy wear.

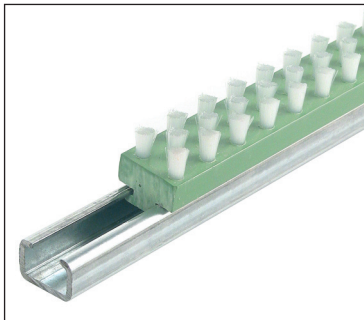

Easy maintenance

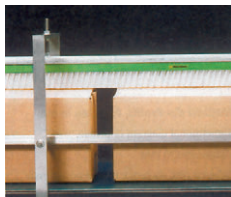

Typical application

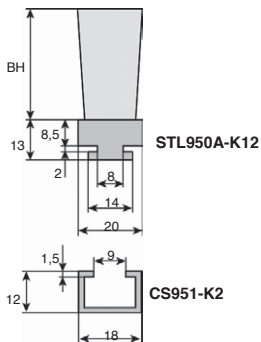

### DISCOUNTS

Qty.	1+	50+	150+	250+
Disc. List	-10%	-15%	On request	

Part number	Length L (mm)	Fibre Ø (mm)	BH	Stock*	Price each 1 to 49
<b>Brush</b>					
STL950A-K12	2000	0,2	8	✓	22,27 €
<b>Rail</b>					
CS951-K2	2000	-	-	✓	16,28 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



AT5-10ECO

Puleggia dentata di posizionamento tipo AT, Serie economica - AT5 al...



TK

Manicotto a sfere autoallineante Topball, Autoallineante,



T5M T10M

Cinghia aperta al metro tipo T, T10 Poliuretano armatura in acciaio



SLB

Pistoncino a molla, inox



BOX-TOR-C

Valigetta di guarnizioni toriche in nitrile, 3.00 x 1.50mm a 30.20 x...



BAC105

Contenitore a becco, 8mm



VELM6

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide



PTAF80-PAMF80

Piede fissabile con base lamiera Ø80, Ø 80



PRF1932

Profilato alluminio standard, 19 x 32 mm




BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla



HSE-HSB

Distanziatore esagonale, Ottone

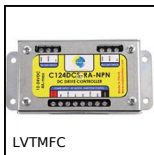

LVTMFC

Device for controlling limit switches, For mini-actuator LVT

## Prodotti correlati



STL

Guida con spazzola, Binario



GMK17\_BROSSE

Spazzola, Per imbottigliamento e imballaggio