



# Guidance brush


## Rigid support

## STL


- For guidance and transport
- Easy maintenance
- Materials:  
base: green PVC  
brush: PA6 transparent straight fibres  
rail: galvanised steel

### Advantages


- In case of they need to be replaced, these strip brushes can be quickly removed from the rails
- Their use is recommended in applications where the fibres will be subject to heavy wear.

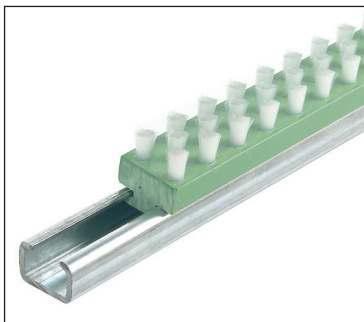

Easy maintenance

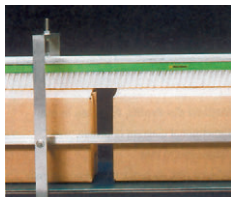

Typical application

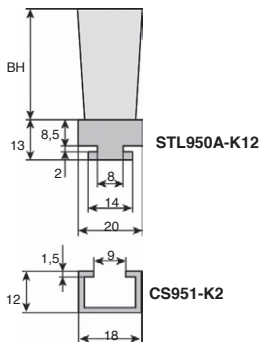

### DISCOUNTS

Qty.	1+	50+	150+	250+
Disc. List	-10%	-15%	On request	

Part number	Length L (mm)	Fibre Ø (mm)	BH	Stock*	Price each 1 to 49
<b>Brush</b>					
STL950A-K12	2000	0,2	8	✓	22,27 €
<b>Rail</b>					
CS951-K2	2000	-	-	✓	16,28 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



UTKswc

Guida lineare Utilitrack®, Ruota di precisione a V in acciaio



PF30Nm

Riduttore a ruota e vite senza fine, fino a 8.8 Nm



DOMI120

Slitta di regolazione Domino 120, Slitta DOMILINE 120



PTA40ssEB

Articulated foot whit sheet metal base Ø40, 3000N



BIMSS

Pistoncino a molla, Miniatura inox



MRA

Maglia rapida, Acciaio



NSO

Supporto standard per manicotto aperto a sfere, Aperto - lungo



SRG

Chiusura a leva regolabile, Corsa da 96mm a 121,7mm



PR821

Ruota di rinvio, Serie 821 e 805



VPPTss

Volantino pieno con impugnatura girevole,



VTHbr

Vite a testa esagonale - DIN933, Ottone



BTCW

Tappo inox per tubo quadrato, A saldare

## Prodotti correlati



STL

Guida con spazzola, Binario



GMK17\_BROSSE

Spazzola, Per imbottigliamento e imballaggio