



# Guidance brush


## Rigid support

## STL


- For guidance and transport
- Easy maintenance
- Materials:  
base: green PVC  
brush: PA6 transparent straight fibres  
rail: galvanised steel

### Advantages


- In case of they need to be replaced, these strip brushes can be quickly removed from the rails
- Their use is recommended in applications where the fibres will be subject to heavy wear.

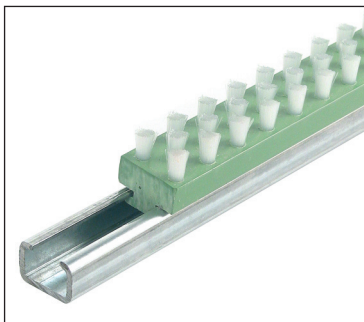

Easy maintenance

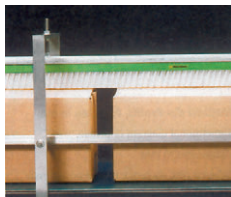

Typical application

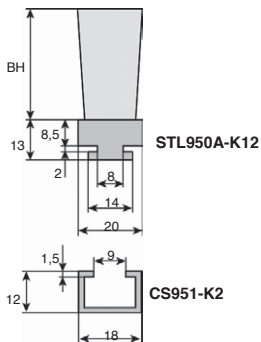

### DISCOUNTS

Qty.	1+	50+	150+	250+
Disc. List	-10%	-15%	On request	

Part number	Length L (mm)	Fibre Ø (mm)	BH	Stock*	Price each 1 to 49
<b>Brush</b>					
STL950A-K12	2000	0,2	8	✓	22,27 €
<b>Rail</b>					
CS951-K2	2000	-	-	✓	16,28 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



RTT  
Calettatore di bloccaggio, Coppia media/elevata



PRF\_CHA\_D  
Cerniera ad avvitare, Scardinabile



BPPE  
Sfera portante, Leggero



GLT2-17  
Guide telescopiche per montaggio in scanalatura, Estensione parziale




PITA  
Pistoncino a molla, con maniglia a T




MRA\_SS  
Maglia rapida, Inox



INStool  
Boccola autofilettante - Attrezzo, Strumento di posa

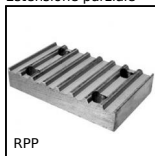

RPP  
Piastra di giunzione per cinghia RPP, RPP5

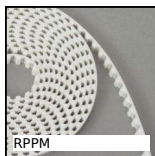

RPPM  
Cinghia aperta al metro tipo RPP, RPP14 Poliuretano armatura



PSG2  
Ingranaggio dritto di precisione, Acciaio 20NCd2 cementato



MDB\_MTB  
Ingranaggio conico in plastica stampata, 3:1



NSB  
Supporto standard per manicotto chiuso a sfere, Chiuso - Lungo

## Prodotti correlati



STL  
Guida con spazzola, Binario



GMK17\_BROSSE  
Spazzola, Per imbottigliamento e imballaggio