


# Threaded adjustable feet



## TAD

## Plastic and steel

- Adjustable feet
- Tilt angle : 25°
- Materials:  
Base: polyethylene or polypropylene  
Rod: mild steel, bright zinc plated

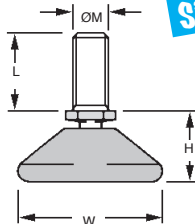

**Simplest solution**



**Economy range**

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØM	L	W	H	Max. static load (kg)	Material	Stock	Price each 1 to 5
TAD5008-25-1	M6	12,5	25	20	50	Polyéthylène	✓	1.42 €
TAD5009-25-1	M6	25,0	25	20	50	Polyéthylène	✓	1.58 €
TAD5010-25-1	M8	12,5	25	20	50	Polyéthylène	✓	1.64 €
TAD5011-25-1	M8	25,0	25	20	50	Polyéthylène	✓	1.71 €
TAD5013-25-1	M10	15,0	25	20	50	Polyéthylène	✓	1.71 €
TAD5014-25-1	M10	37,5	25	20	50	Polyéthylène	-	on request
TAD5015-25-1	M10	50,0	25	20	50	Polyéthylène	✓	2.45 €
TAD5019-25-1	M12	50,0	25	20	50	Polyéthylène	-	2.01 €
TAD5008-40-1	M6	12,5	40	20	100	Polyéthylène	-	1.88 €
TAD5009-40-1	M6	25,0	40	20	100	Polyéthylène	-	1.58 €
TAD5010-40-1	M8	12,5	40	20	100	Polyéthylène	-	1.29 €
TAD5011-40-1	M8	25,0	40	20	100	Polyéthylène	✓	1.99 €
TAD5013-40-1	M10	15,0	40	20	100	Polyéthylène	-	1.77 €
TAD5014-40-1	M10	37,5	40	20	100	Polyéthylène	✓	1.64 €
TAD5015-40-1	M10	50,0	40	20	100	Polyéthylène	✓	1.93 €
TAD5019-40-1	M12	50,0	40	20	100	Polyéthylène	✓	2.01 €
TAD5008-55-1	M6	12,5	55	20	100	Polypropylène	-	2.45 €
TAD5009-55-1	M6	25,0	55	20	100	Polypropylène	-	2.63 €
TAD5010-55-1	M8	12,5	55	20	100	Polypropylène	-	2.28 €
TAD5011-55-1	M8	25,0	55	20	100	Polypropylène	✓	2.33 €
TAD5013-55-1	M10	15,0	55	20	250	Polypropylène	-	2.36 €
TAD5014-55-1	M10	37,5	55	20	250	Polypropylène	✓	2.75 €
TAD5015-55-1	M10	50,0	55	20	250	Polypropylène	✓	3.10 €
TAD5019-55-1	M12	50,0	55	20	250	Polypropylène	✓	2.53 €

\*Depending on availability

## Altri prodotti...



P60  
Riduttore a ruota e vite senza fine, fino a 118 Nm




GE  
Chiusura a leva, Standard



SVG  
Chiusura a leva regolabile, Corsa da 174mm a 190mm




AC  
Piastrina di riscontro, 12,13,18 e 20mm

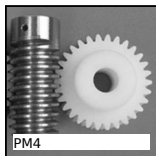

PM4  
Coppia ruota e vite senza fine, Plastica lavorata (delrin)



GBSz  
Vite a ricircolo di sfere, Dado cilindrico

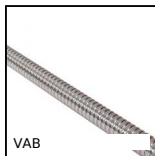

VAB  
Vite a ricircolo di sfere al metro, Vite a sfere rullata, al metro



DOMI120  
Slitta di regolazione Domino 120, Slitta DOMILINE 120



SSB  
Ingranaggio conico inox, 1:1



ES  
Support base (tripod), Plastic



SERB  
Interblocco di sicurezza, Chiave



PRF\_PIV  
Cerniere e giunti, Fulcro per porta

## Prodotti correlati



FAD  
Piede snodato semplice, Piede inclinabile senza suola antiscivolo