


## - Tensioner for single chain

## - Materials:

Housing and column: polyamide reinforced with 30% glass fibre

Profile: Green HD1000 polyethylene

Screws and springs: stainless steel 304L

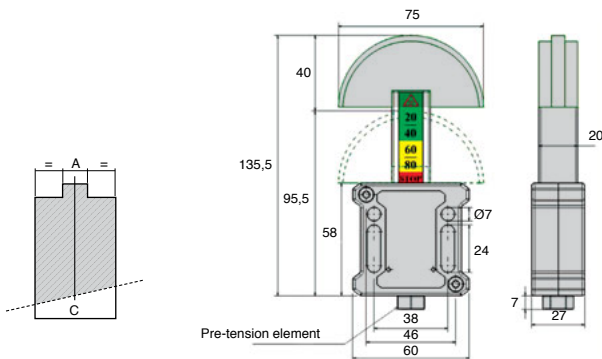

## DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Chain	A	C	Stroke	Tension (N)	Price each
TCSH-06B1	06B1	5	20	40	100 to 240	36,18 €
TCSH-08B1	08B1	7	20	40	100 to 240	36,18 €
TCSH-10B1	10B1	9	20	40	100 to 240	36,18 €
TCSH-12B1	12B1	11	20	40	100 to 240	36,18 €

Dimensions in mm

## Altri prodotti...



PRF\_GAL

Rotella per profilo alluminio, Kit di fissaggio per rotella concentrica...




PRF\_PGN

Maniglia e battuta per porta, Maniglia con serratura



OP2

Indicatore di posizione digitale (N. di giri), 3 cifre

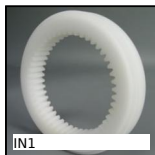

IN1

Ingranaggio interno, Plastica lavorata (delrin)



G-ECO

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



ALIDR30

Alimentazione, 1,5 A and 2 A



T5M\_T10M

Cinghia aperta al metro tipo T, T10 Poliuretano armatura in acciaio



SER

Accessori per porte, Fermoporte a calamita



TK\_UUOP

Manicotto a sfere autoallineante



CFF

Testa a snodo femmina DIN



DER80

Motore inox AC asincrono da 0,55 a



M0


Coppia ruota e vite senza fine, Bronzo

## Prodotti correlati



SUA4

Catena semplice al metro, Acciaio

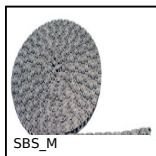


SBS\_M

Catena semplice al metro, Inox



PCS50

Pignone a catena - acciaio, 12.7mm (DIN08B-1)

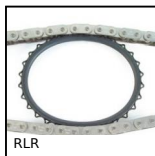

RLR

Tenditore per catena Roll-Ring®, Roll-Ring® Self-adjusting