

**- Tensioner for single chain****- Materials:**

Housing and column: polyamide reinforced with 30% glass fibre


Screws and springs: stainless steel 304L

Steel version: bracket and sprocket steel

Stainless steel version: bracket, axle and nut

stainless steel 304L, stainless steel sprocket, sprocket bearing lubricated for life (FM 222 grease suitable for food industry acc USA standards).

steel or  
stainless  
steel

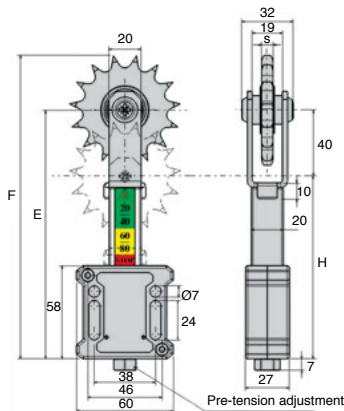**DISCOUNTS**

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Chain Pitch	N° of teeth	S	Øext	ØPCD	F	E	H	Stroke	Tension Price each		
										(N)	1 to 9	
<b>Steel sprocket</b>												
TCRX-06B1	06B1	9,525	15	5,3	49,3	45,81	160	135,0	95,0	40	100 to 240	61,32 €
TCRX-08B1	08B1	12,700	15	7,2	65,5	61,09	186	153,5	113,5	40	100 to 240	60,72 €
TCRX-10B1	10B1	15,875	15	9,1	83,0	76,36	196	153,5	113,5	40	100 to 240	64,84 €
<b>Stainless steel sprocket</b>												
TCRX-06B1/SS	06B1	9,525	15	5,3	49,3	45,81	160	135,0	95,0	40	100 to 240	75,69 €
TCRX-08B1/SS	08B1	12,700	15	7,2	65,5	61,09	186	153,5	113,5	40	100 to 240	80,52 €
TCRX-10B1/SS	10B1	15,875	15	9,1	83,0	76,36	196	153,5	113,5	40	100 to 240	102,84 €


Dimensions in mm

## Altri prodotti...



WSRM

Dado cilindrico in polimero, Polimero (Iglidur®) - 1 filetto

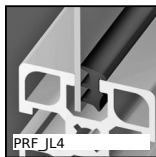

PRF\_JL4

Panel accessories, Guarnizione - Ø 4mm



PRF-SCL

Sistema di chiusura per profili alluminio, Lock for sliding doors



GB-RA

Ingranaggio dritto ottone, Ottone CuZn39Pb3



H3

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



PGMSS

Maniglia a ponte inox, Inox



CHAL3

Cerniera piana, Alluminio




DBL880

Rotella per catena, Serie 880 e 881




MHMEP

Manovella ad impugnatura girevole,

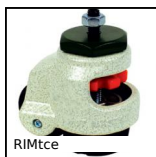

RIMtce

Ruota di livellamento, Con foro centrale

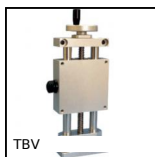

TBV


Tavola di posizionamento



UFX


Giunto elastico UNEFLEX, range

## Prodotti correlati

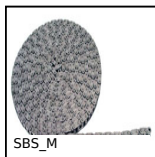

SBS\_M

Catena semplice al metro, Inox

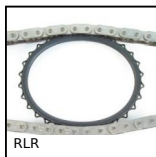

RLR

Tenditore per catene Roll-Ring®, Roll-Ring® Self-adjusting



PCS37SS

Pignone a catena - Inox, 9.525 (DIN 06B-1)