

**- Tensioner for single chain****- Materials:**

Housing and column: polyamide reinforced with 30% glass fibre


Screws and springs: stainless steel 304L

Steel version: bracket and sprocket steel

Stainless steel version: bracket, axle and nut

stainless steel 304L, stainless steel sprocket, sprocket bearing lubricated for life (FM 222 grease suitable for food industry acc USA standards).

steel or  
stainless  
steel

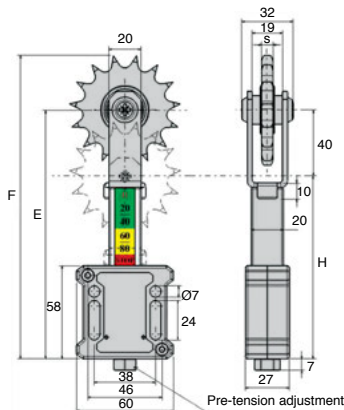**DISCOUNTS**

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Chain Pitch	N° of teeth	S	Øext	ØPCD	F	E	H	Stroke	Tension (N)	Price each	
											1 to 9	
<b>Steel sprocket</b>												
TCRX-06B1	06B1	9,525	15	5,3	49,3	45,81	160	135,0	95,0	40	100 to 240	61,32 €
TCRX-08B1	08B1	12,700	15	7,2	65,5	61,09	186	153,5	113,5	40	100 to 240	60,72 €
TCRX-10B1	10B1	15,875	15	9,1	83,0	76,36	196	153,5	113,5	40	100 to 240	64,84 €
<b>Stainless steel sprocket</b>												
TCRX-06B1/SS	06B1	9,525	15	5,3	49,3	45,81	160	135,0	95,0	40	100 to 240	75,69 €
TCRX-08B1/SS	08B1	12,700	15	7,2	65,5	61,09	186	153,5	113,5	40	100 to 240	80,52 €
TCRX-10B1/SS	10B1	15,875	15	9,1	83,0	76,36	196	153,5	113,5	40	100 to 240	102,84 €


Dimensions in mm

## Altri prodotti...



NPTR

Morsetto, Regolabile

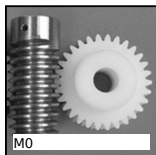

M0

Coppia ruota e vite senza fine , Plastica lavorata (delrin)



PRF1932

Profilato alluminio standard, 19 x 32 mm



CABtool

Attrezzi per cavi, Attrezzi per crimpatura



CAP820

Catena a tapparella dritta, Stretta serie 820



ADL\_F

Anello di sollevamento, Inox



RTTss

Calettatore di bloccaggio, Coppia media/elevata



QNJ

Cuscinetto a singola corona di rulli cilindrici, Anello interno fiss...



T10courroie

Cinghia di posizionamento T, T10 Poliuretano armatura in acciaio



PHT

Maniglia a ponte, Fino a 250°C



M1

Coppia ruota e vite senza fine , Acciaio non temprato



PARF80


Piede senza snodo, Piede snodato oscillante fissabile Ø80

## Prodotti correlati



SUA4

Catena semplice al metro, Acciaio

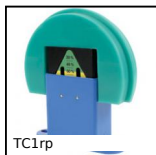


TC1rp

Tenditore per catena automatico, Con pattino 180°



PCS37

Pignone a catena - acciaio, 9.525mm (DIN06B-1)

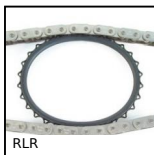

RLR

Tenditore per catena Roll-Ring®, Roll-Ring® Self-adjusting