

TIF

Stainless steel A2

- **Conforms to DIN 975**
- **Material:**
Stainless steel: 303/304 - A2
- **Working temperature up to +430°C**

Uses


- Suitable for harsh environments

Options

- Stainless steel 316

Accessories

- Nuts **SHN**
- Stainless steel screws

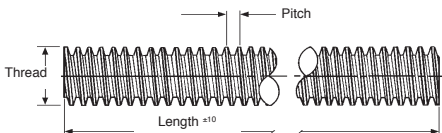

DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Thread	Pitch	Length (mm)	Stock*	Price each 1 to 5
TIF-2/SS	M2	0,40	1000	✓	9,39 €
TIF-2.5/SS	M2,5	0,45	1000	✓	10,31 €
TIF-3/SS	M3	0,50	1000	✓	3,74 €
TIF-4/SS	M4	0,70	1000	✓	3,72 €
TIF-5/SS	M5	0,80	1000	✓	2,58 €
TIF-6/SS	M6	1,00	1000	✓	2,84 €
TIF-8/SS	M8	1,25	1000	✓	5,34 €
TIF-10/SS	M10	1,50	1000	✓	8,57 €
TIF-12/SS	M12	1,75	1000	✓	12,39 €
TIF-14/SS	M14	2,00	1000	✓	17,04 €
TIF-16/SS	M16	2,00	1000	✓	20,71 €
TIF-18/SS	M18	2,50	1000	✓	30,29 €
TIF-20/SS	M20	2,50	1000	✓	33,72 €
TIF-22/SS	M22	2,50	1000	-	44,78 €
TIF-24/SS	M24	3,00	1000	-	48,29 €
TIF-27/SS	M27	3,00	1000	-	73,40 €
TIF-30/SS	M30	3,50	1000	-	92,83 €
TIF-33/SS	M33	3,50	1000	-	118,04 €
TIF-36/SS	M36	4,00	1000	-	125,44 €

*Depending on availability


Altri prodotti...



PRF-SCREEN-1
Screen support, Basic support



BSM_LOK
Pressore a molla con esagono incassato, LONG-LOK - corpo e spina ino...

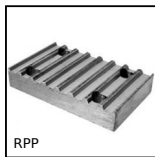

RPP
Piastra di giunzione per cinghia RPP, RPP14



PTKFss
Piede fissabile speciale agroalimentare, Stainless steel - 3-A



S_ZZ
Cuscinetto radiale a sfere, Inox



SHN
Dado esagonale - DIN934, Acciaio (Class 6|8)



DOG258
Motoriduttore DC 12V e 24V DC, da 12 a 15 Nm



CLM
Attacco per forcella, Corta inox



T5M_T10M
Cinghia aperta al metro tipo T, T10 Poliuretano armatura



DHX
Spina cilindrica filetto interno, estraibile DIN 7979D



CHAR
Cerniera a molla, avvitabile



PLM-SC
Magnete piatto con foro svasato, Con foro fresato

Prodotti correlati



SHN
Dado esagonale - DIN934, Inox A2



SHW
Rondella semplice, Inox A2



MCL
Manicotto cilindrico maschiato, Cilindrico - inox



MHX
Manicotto esagonale maschiato, Esagonale - inox