

# Fixed castor for aluminium profile

For loads up to 120kg

TPEF

- Castor for aluminium profil 40/45mm such as PRF4545

- Materials:

Plate: powder-coated steel sheet,

natural aluminium colour

Wheel: grey polypropylene (RAL 7001)

## Advantages


- Silent
- Will not mark floor
- Low rolling resistance

## Info

- Fixing screws not supplied  
(See PRF-ECL-M8 and BHC8/CHC8 screws)



Typical application

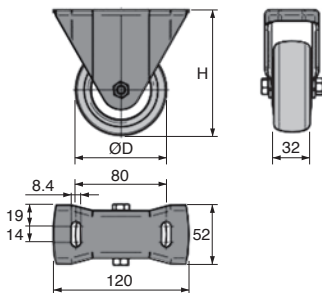

## DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%	On request	

Part number	ØD	H	Maximum load (N)	Weight (g)	Price each 1 to 9
TPE80/F	80	111	1000	484	22,14 €
TPE100/F	100	136	1100	577	26,60 €
TPE125/F	125	161	1200	675	29,80 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

279

## Altri prodotti...



PRF\_FIX\_UNI  
Fissaggio, universale



GE32  
Chiusura a leva rigida  
ad anello, Standard



DOMI80  
Accessori di  
collegamento, Piatto  
girevole



EV  
Terminale rapido inox  
per cavi,



PW\_PWG2  
Ruota di precisione,  
Bronzo



MEB  
Ingranaggio conico in  
plastica stampata, 1:1



MPE  
Distanziatore  
esagonale, Acciaio




PW\_PWG1  
Ruota di precisione,  
Bronzo



BABS  
Perno autobloccante a  
sfere inox 630, Inox



PLM-SC  
Magnete piatto con  
foro svasato. Con foro

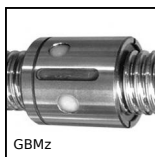

GBMz  
Dado per vite a sfere,  
Dado cilindrico a



PRF3232  
Profilato alluminio  
standard, 32 x 32 mm

## Prodotti correlati



TPEpbd  
Ruota per profili  
alluminio, Girevole  
con freno



PRF4545  
Profilato alluminio  
standard, 45 x 45 mm



PRF\_ECL\_  
Fissaggio, Dado  
quadrato con  
linguetta - Acciaio



BHC  
Vite a testa bombata  
BHC , Inox A2