

Swivel castor for aluminium profile

TPEPDB

For loads up to 120kg

- Swivel castor with brake for use with aluminium profile 40/45mm such as PRF4545

- Material:

Plate: powder-coated steel sheet,
natural aluminium colour

Wheel: grey polypropylene (RAL 7001)

Advantages

- Silent
- Will not mark floor
- Low rolling resistance


Info

- Fixing screws not supplied

(See PRF-ECL-M8 and BHC8/CHC8 screws)



Typical application

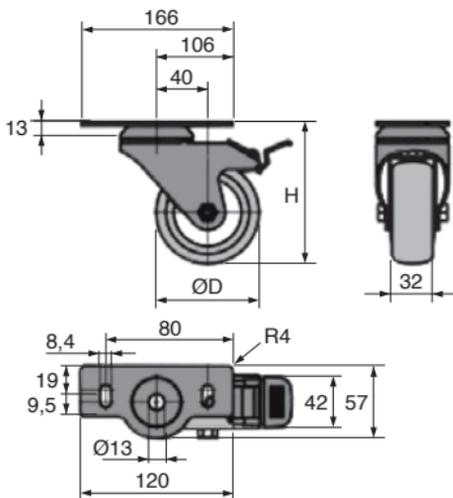

REMISES

Qté	1+	10+	30+
Rem. Prix	-5%	Sur demande	

Part number	ØD	H	Maximum load (N)	Weight (g)	Price each 1 to 9
TPE80/PDB	80	111	1000	710	32.11 €
TPE100/PDB	100	136	1100	787	35.05 €
TPE125/PDB	125	161	1200	873	37.15 €

Dimensions in mm

Altri prodotti...



EZYSS

Piedino antivibrante cilindrico inox, inox



SVT30

Martinetto a vite - Vite traslante, Vite traslante



SCE_SS

Serracavo, Inox



CLM

Attacco per forcella, Corta inox



BPVMss

Sfera portante avvitabile miniatura, Miniatura ad avvitare



DFG

Ventosa, nitrile



GB-RA

Ingranaggio dritto ottone, Ottone CuZn39Pb3



PRF_PIV

Cerniere e giunti, Fulcro per porta



TB_ECO

Ingranaggio conico - Acciaio C43 - ECO, 3:1



GB-RA

Ingranaggio dritto ottone, Ottone CuZn39Pb3



RBG

Ruota, Rivestimento in gomma - nucleo in polipropilene



GLB

Volantino a 6 lobi filettato, Tecnopolimero - Inox

Prodotti correlati



TPEF

Ruota per profili alluminio, Fissa



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



CHC

Vite a testa cava esagonale CHC, Acciaio classe 12.19