


- **Structural tube**
- Materials: Stainless steel or anodised aluminium
- Square tube 25 x 25mm

Accessories

- Connectors **NCT**
- Caps **BTC**
- Slide profiles **PGT**
- Support profiles **PSP**

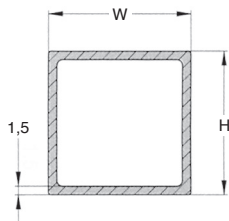

DISCOUNTS

Qty.	1+	10+	21+
Disc.	List -5%	On request	

Part number	Material	H	W	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 9
TUBE25-25/SS	Stainless steel	25	25	3000	3,21	✓	70,08 €
TUBE25-25/AL	Aluminium	25	25	3000	1,09	✓	48,20 €

*Depending on availability - Dimensions in mm

Altri prodotti...



PRF_CLIP_45

Clip di fissaggio per cavi per profili alluminio, Per canalina di ca...



DFG

Ventosa, silicone



VRM

Anello di sollevamento, Orientabile femmina



BPM

Pressore a molla con intaglio e puntale a sfera, Acciaio



UCF_PBT

Cuscinetto a flangia quadrata polimero inox, Polimero e inox



WSRM

Dado cilindrico in polimero, Polimero (Iglidur®) - 1 filetto



PSG1

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



MHXred

Manicotto di riduzione, Esagonale - inox



RGS

Giunto senza gioco Rotex® GS, da 0.5 a 190Nm



EHD06

Riduttore coassiale, da 8 a 19 Nm



HAR9

Rondella girevole, DIN 6371



PO

Maniglia a ponte - Multi-settore, Foro cieco maschiato

Prodotti correlati



BTC

Tappo per tubo quadrato, Standard



NCT_AT

Giunto di collegamento, Ad angolo variabile



NCT

Giunto di collegamento, Ad angolo fisso



NCT

Giunto di collegamento, Ad angolo fisso